


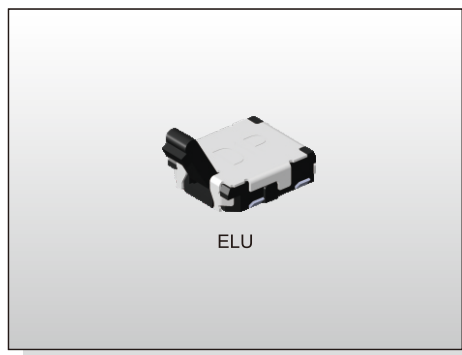

ELU

FEATURES

- ※ Compact sized
- ※ Sharp detection feeling


APPLICATION

- ※ Consumer electronics
- ※ Safety control device
- ※ Heat energy regulator

SPECIFICATION

Contact Rating	100μA, 3V DC min. 1mA, 5V DC max.
Contact Resistance	3Ω max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	100V AC/1 minute
Operating Force	35gf max.
Travel	2.50mm
Operating Life	50,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

CIRCUIT

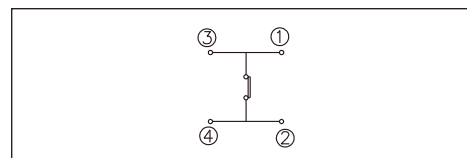

PACKAGE

<Tape & Reel>
2000 pcs

HOW TO ORDER

ELU ☐ ☐ ☐ QR

☐=Without Post
P=With Post




Terminal Type :
F=With Flat Terminal
L=With Bending Terminal

Package:
Tape & Reel

Halogen Free

Circuit:
C=Normal Close
☐=Normal Open

ELU

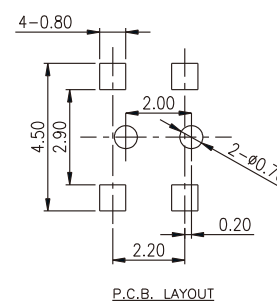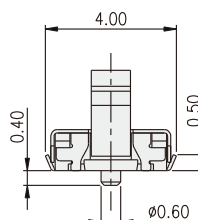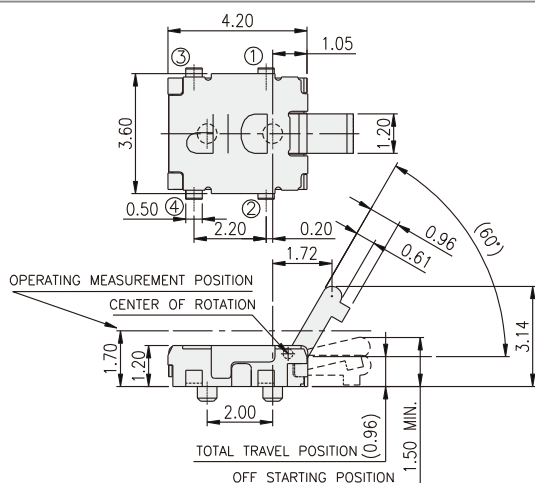

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[ELULCQR](#) [ELUFCQR](#) [ELUPFCQR](#)