



FEATURES

- ※Sharp click feeling with soft sound
- ※Long travel
- ※Sealed IP67

APPLICATION

- ※Automotive
- ※Instrument
- ※Industrial

SPECIFICATION

Contact Rating	10uA, 1V DC min. 50mA, 16V DC max.
Contact Resistance	100mΩ max.(initial)
Insulation Resistance	100MΩ min.
Dielectric Strength	250V AC/1 minute
Operating Force	350±90gf
Operating Life	100,000 cycles min.
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-55°C ~ +85°C


HOW TO ORDER

T 6 V J **G Q R**

J Bend ————
Total Height: 1=4.9mm
Operating Force: 1=350gf

Package: Tape & Reel
Halogen Free
Plating: G=Silver Plating

CIRCUIT




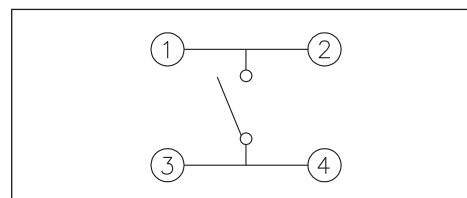


PACKAGE

<Tape & Reel>
1000 pcs

TACT SWITCH

T6VJ

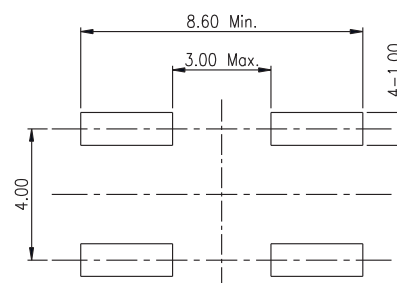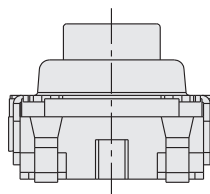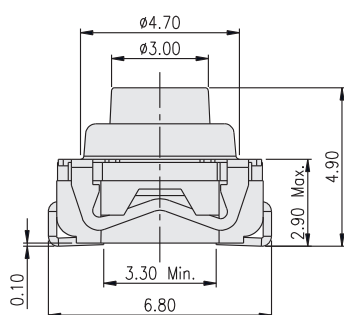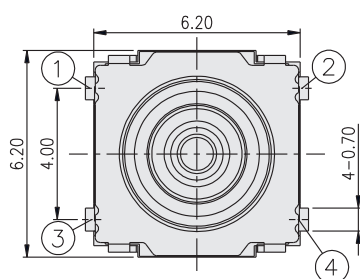

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Diptronics:](#)

[T6VJ11GQR](#)