

ILLUMINATED SWITCH



- ※Various LED options
- ※300,000 operating life cycles

- ※Automotive
- ※Network equipment
- ※Telecommunications
- ※Medical equipment
- ※Industrial controls

Contact Rating	50mA, 32V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	400±100gf
Travel	0.45mm
Operating Life	300, 000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-55°C ~ +85°C

ML 9 - M **QR**

S.M.T.

☐=Without Post
P=With Post



Operating Force:
4=400gf

Package:
Tape & Reel

Halogen Free

LED Color:
☐=Without LED
B=Blue
G=Green
R=Red
W=White
Y=Yellow
A=Amber

<Tape & Reel>
650 pcs.

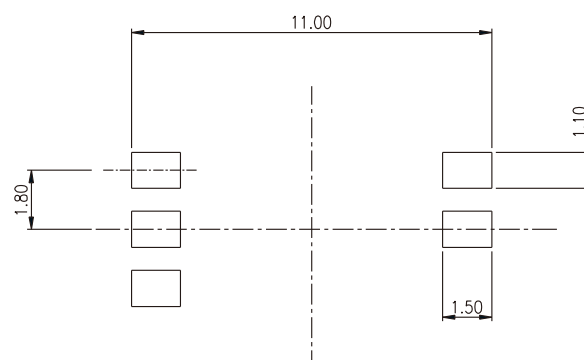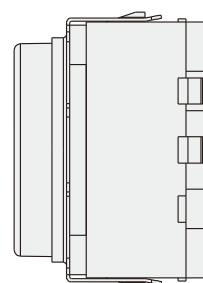

P.C.B. LAYOUT

Date code: YYMMDD

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[ML9-M4RQR](#) [ML9-M4WQR](#) [ML9-M4GQR](#) [ML9-MP4YQR](#) [ML9-M4YQR](#) [ML9-MP4AQR](#) [ML9-MP4BQR](#) [ML9-MP4GQR](#) [ML9-MP4RQR](#) [ML9-MP4WQR](#) [ML9-M4AQR](#) [ML9-M4BQR](#)