

FEATURES

- ※High operating force
- ※Long stroke
- ※300,000 operating life cycles

APPLICATION

- ※Automotive
- ※Measuring instruments
- ※Car audio

SPECIFICATION

Contact Rating	50uA, 1V DC to 50mA, 16V DC
Contact Resistance	100mΩ max. (initial)
Insulation Resistance	100MΩ min.
Dielectric Strength	500V AC/1 minute
Operating Force	300±80gf/360±80gf
Travel	1.05mm
Operating Life	300,000 cycles min.
Operating Temp.	-40°C ~ +90°C
Storage Temp.	-40°C ~ +90°C

HOW TO ORDER

T 6 S J □ G Q R

J Bend


Package:
Tape & Reel

Operating Force:
K=Black, 360gf
W=White, 300gf

Halogen Free

Plating:
Silver Plating





CIRCUIT

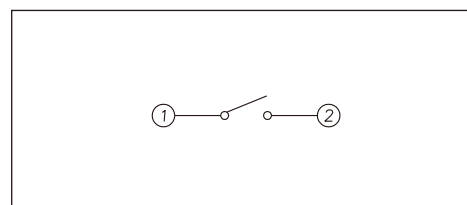

PACKAGE

<Tape & Reel>
1500 pcs

T6S

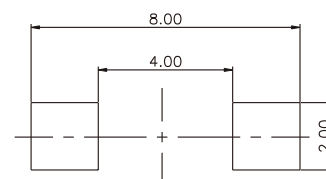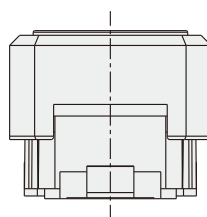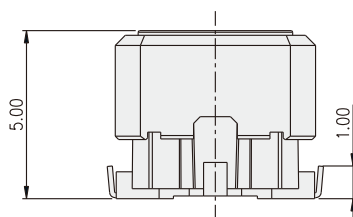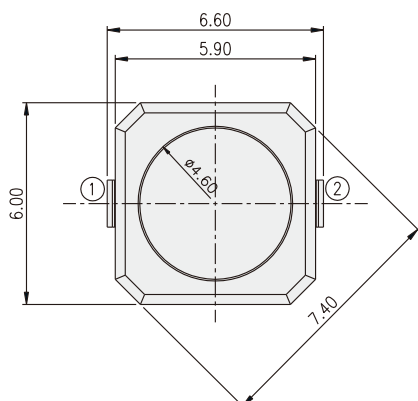

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

T6SJKGQR