

Remote LED display - Input 0-10 V RD Part number 88950400



- Highlight the data of your automation application
- Display (36 x 72 mm) with 4 x 14 mm red digits
- Configurable display range
- 0-10 V input
- IP65 degree of protection on front panel

Part numbers

	Type	Description	Supply
88950400	RD	Display with 4 x 14 mm red digits	24 V DC

Specifications

Environmental characteristics

Certifications	CE
Conformity to standards	IEC/EN 61000-6-4, IEC/EN 61010-1
Protection rating	In accordance with IEC/EN 60529 : IP65 on front panel IP20 on rear
Operating temperature	-10 → +55 °C
Dimensions (l x h x w)	36 x 72 x 61 mm
Panel cut-out	71 x 29 mm

Electrical characteristics

Supply	24 V DC
Tolerance	± 10 %
Consumption	< 1 W
Input voltage	0 → 10 V DC

Mechanical characteristics


Mounting	Flush-mounted
Connection	Terminal block

Display characteristics

Height of digits	14 mm
Number of digits	4
Colour	Red
Range	-1999...5999 with selectable decimal point
Device accuracy (full scale)	≤± 0.3 % of interval

Comments

Dimensions (mm)

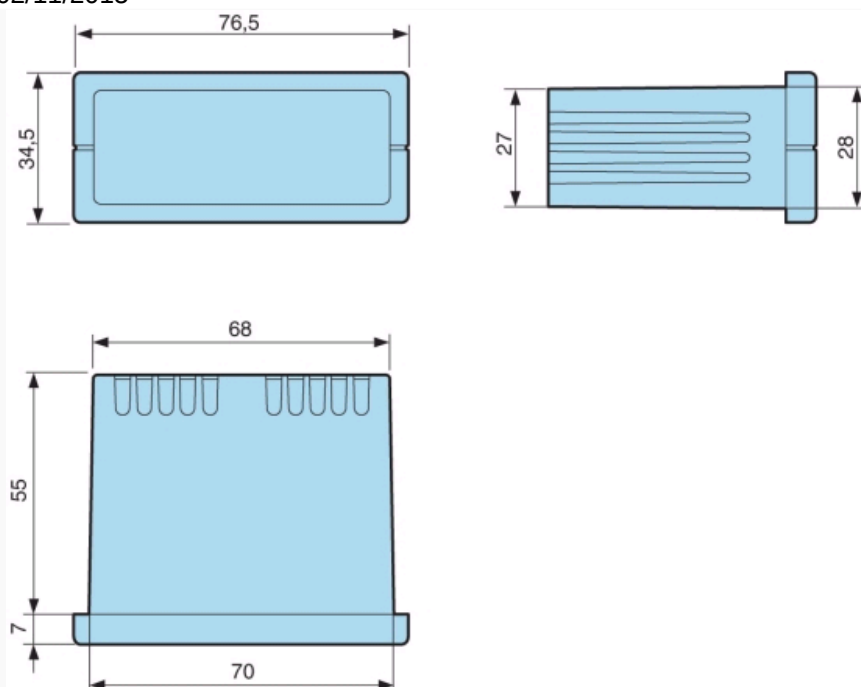

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Crouzet:

88950400