




CRYSTEK
MICROWAVE
A DIVISION OF CRYSTEK CORPORATION

RG58A/U N-TYPE RF COAX CABLE ASSEMBLIES



RG58A/U 50 ohms
N-Type Coaxial Cable Assemblies

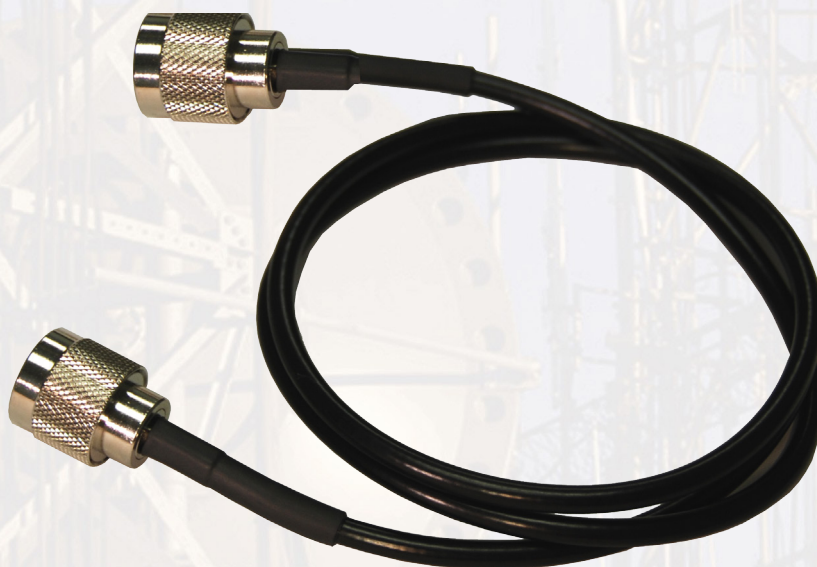

Features:

- Strain Relief:** Adhesive shrink tubing over crimp area
- Center Conductor:** TPC (Tin-Plated Copper) 19/0072
- Shielding:** TPC (Tin-Plated Copper) 96% Coverage, Single Braid
- Dielectric:** Solid Polyethylene
- Jacket:** PVC (Polyvinyl Chloride) Black
- Operating Temperature:** -40°C to +80°C
- Minimum Bend Radius:** 1.0"

Part Number	Description	Length
CCN-MM-RG58-12	RG58A/U Shielded Cable, N-Type Male/Male	12"
CCN-MM-RG58-24	RG58A/U Shielded Cable, N-Type Male/Male	24"
CCN-MM-RG58-36	RG58A/U Shielded Cable, N-Type Male/Male	36"



CRYSTEK
CORPORATION

12730 COMMONWEALTH DRIVE • FORT MYERS, FL 33913

PHONE: 239-561-3311 • 800-237-3061 Rev.: B

FAX: 239-561-1025 • WWW.CRYSTEK.COM Date: 04-07-14

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Crystek:

[CCN-MM-RG58-12](#) [CCN-MM-RG58-24](#) [CCN-MM-RG58-36](#)