 


MARKETING SALES DRAWING


DIMENSIONS IN INCHES - DO NOT SCALE THIS DRAWING
DIMENSIONS IN METRIC - []

This drawing is the property of Tusonix, Inc., and may not be used, reproduced, published or disclosed to others without expressed authorization by Tusonix Inc.


Electrical Testing
per Tusonix standard
test plans and Mil-Std-202
Test Methods.



ORIENTATION

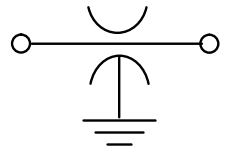

CIRCUIT

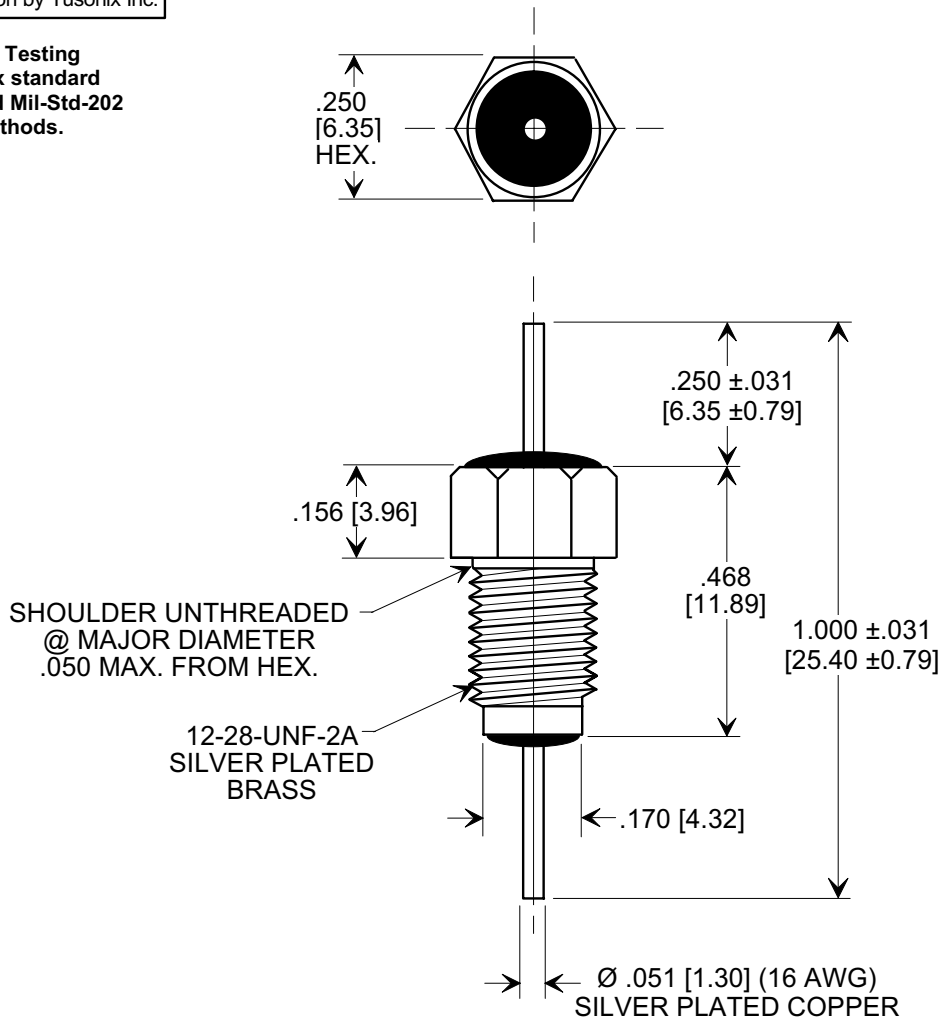

SPECIFICATIONS

TUSONIX STYLE.	2499-003
Capacitance Value:	500 pF
Capacitance Tolerance:	±20%
Temp. Characteristics:	X5U
Rating:	500 WVDC @ 85 °C
Current (A):	20
IR Min @ 100 vdc	10 GΩ
DWV	1500 VDC
Operating Range:	-55° TO + 85°C

NOTES:

- SUPPLIED WITH SILVER PLATED HEX NUT AND INTERNAL TOOTH LOCK WASHER.
- TUSONIX STANDARD PART
 NUMBER: 2499-003-X5U0-501M.
 TUSONIX R.o.H.S. COMPLIANT PART
 NUMBER: 2499-003-X5U0-501M LF.
 CUSTOMER MUST SPECIFY STANDARD OR RoHS PART NUMBER WHEN ORDERING.
- PART MARKING: TRADEMARK, CAPACITANCE CODE AND TOLERANCE CODE STAMPED ON BUSHING HEX FLATS:
 STANDARD PART: BLACK MARKING.
 RoHS COMPLIANT PART: GREEN MARKING.

X-2015 Rev-0	REVISION RECORD	Original Release C.O. 20070321-2-01	0		--TOLERANCES-- Unless Otherwise Specified		Title BUSHING TYPE FEED-THRU CAPACITOR	
					DECIMAL ± .015 [0.38]		Drawn S.M. 03-26-07	
					ANGLES ± 			
					TUSONIX TUCSON, ARIZONA		Approved R.L. 03-26-07	
							A	2499-003-X5U0-501M

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tusonix / CTS:](#)

[2499-003-X5U0-501MLF](#)