

M-Series Pushbutton Switches

Approvals:
Pending

Contact Rating
10A 125/250 VAC
1/4 HP 125 VAC
10A 14 VDC

Contact Material
Fine Silver


Dielectric Strength
2000 VAC RMS

Life
25,000 operations at max. rating - 100,000 mechanical


Terminals
3/16" quick-connect or .050 x .031 p.c.

Lamps
6, 12 and 28 volt incandescent lamps.
125 and 250 volt neon lamps.
6 or 12 volt LED's.

Circuit	Switching	Circuit Diagram (Lighted)	Circuit Diagram (Non-Lighted)
1	Single-Pole Single-Throw Normally Open		
3	Double-Pole Single-Throw Normally Open	N/A	
6	Single-Pole Single-Throw Normally Open		N/A
7	Double-Pole Single-Throw Normally Open		N/A
D	Indicator Light Only		N/A

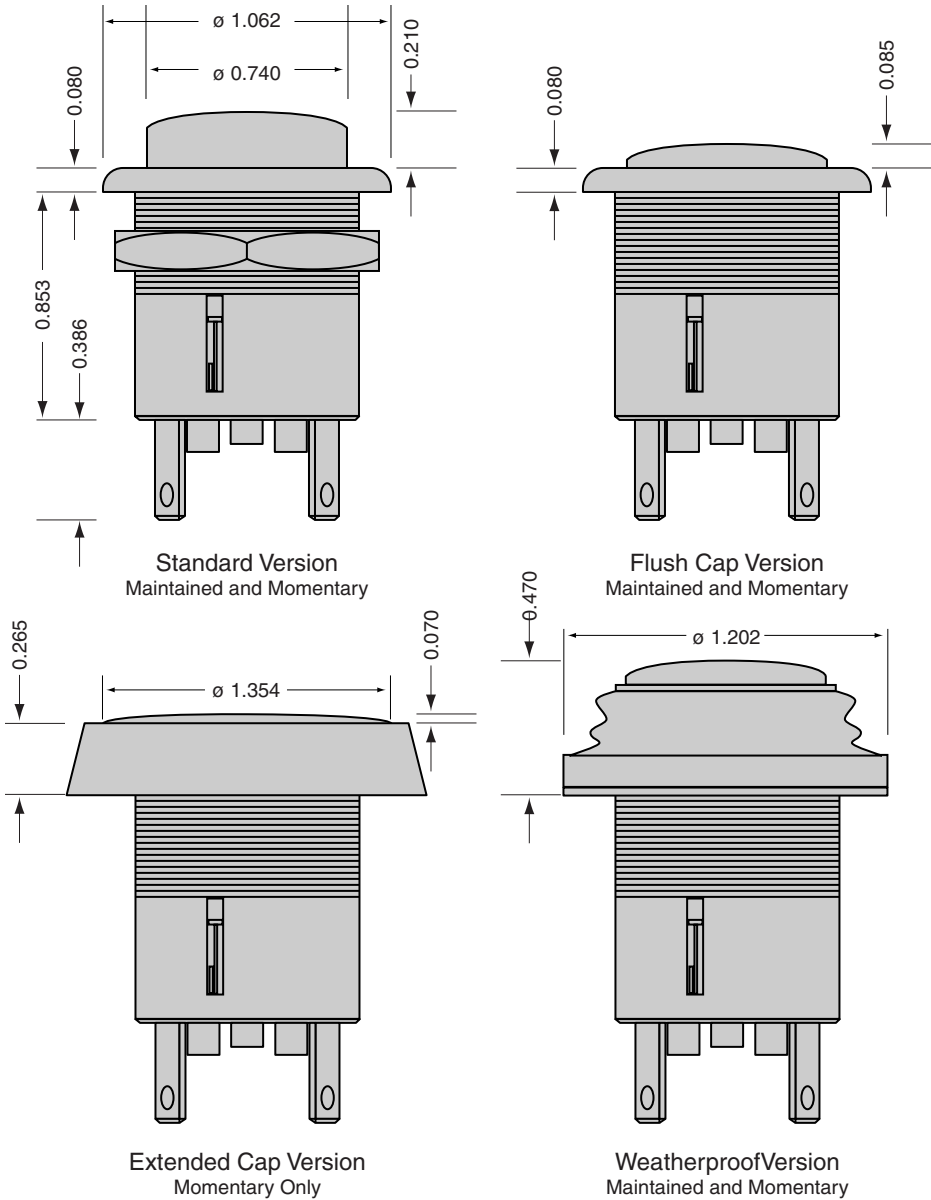

Ordering Information:

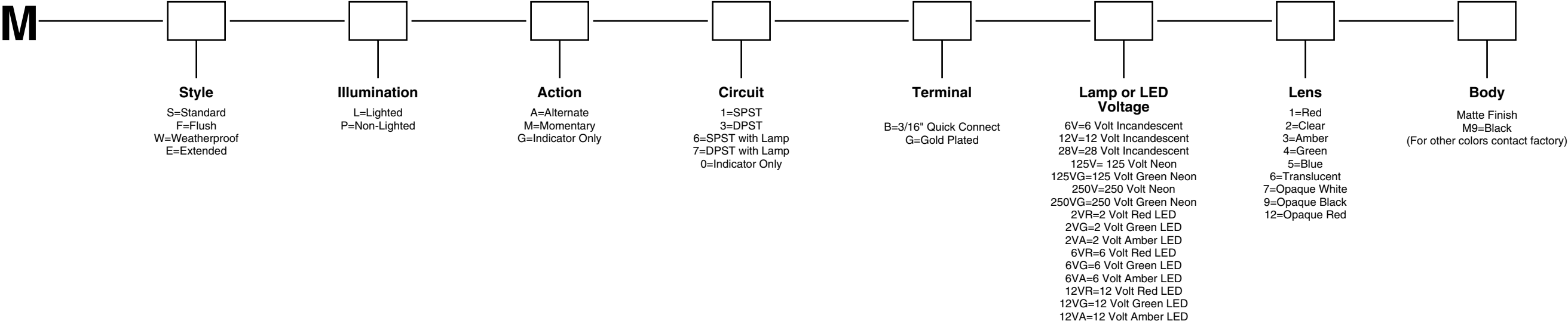

Phone (203) 272-2794 • Fax (203) 272-3492 • <http://www.osloswitch.com>

MADE IN U.S.A.



Phone (203) 272-2794 • Fax (203) 272-3492 • <http://www.osloswitch.com>

MADE IN U.S.A.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CW Industries:

[MFLM1B12VG2M9](#) [MFPM1B9M9](#) [MFLA1B12VA2M9](#) [MWLA1B12VA3M9](#) [MWPM3B4M9](#) [MWPM1B4M9](#)
[MFLA1B12VG4M9](#) [MFLM1B12VG4M9](#) [MFLM6B2VA2M9](#) [MWLM1B12VG4M9](#) [MELM1B12VA3M9](#)
[MWLA6B12VR6M9](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CW Industries:

[MELM1B12VA3M9](#) [MFLM6B2VA2M9](#) [MFPM1B9M9](#) [MWLA1B12VA3M9](#) [MWLM1B12VG4M9](#) [MFLA1B12VA2M9](#)
[MFLA1B12VG4M9](#) [MFLM1B12VG2M9](#) [MFLM1B12VG4M9](#) [MWLA6B12VR6M9](#) [MWPM1B4M9](#) [MWPM3B4M9](#)