


Panel Cutout

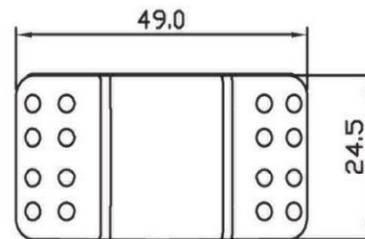

SPECIFICATIONS:

Rating: 25A 12V DC

Function: ON - OFF SPST

Pos 1 Pos 2

Contact Resistance: 20mΩ max. (initial)

Insulation Resistance: 100mΩ min. (at 500V DC)

Dielectric Strength: 1,500V AC 50/60 Hz for 1 minute
Temp. T55

Service Life: Mechanically: 100,000 operations min.

Electrically: 30,000 operations min.


Water Proof: IP68

Base Color- Gray

Actuator Color- Black


MM YY

Date
Code
Label

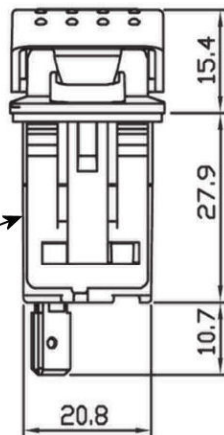

POS 1

POS 2

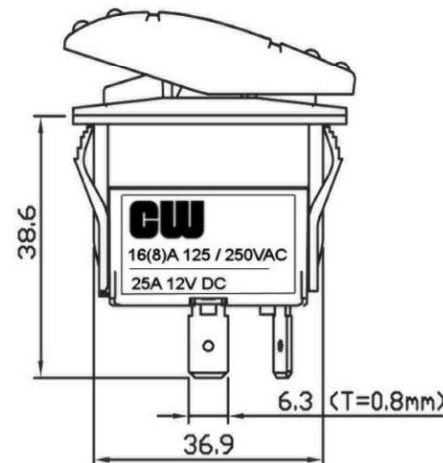

RoHS Compliant

CW INDUSTRIES
Southampton, Pa. 18966
Tel 215.355.7080/www.cwind.com

Date Drawn: 3-19-12

Rev. 0

Unit: mm

Checked By: *G. Gold*

Title:

ROCKER SWITCH

CW P/N:

GRB114A2NABA1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CW Industries:](#)

[GRB114A2NABA1](#) [GRB290AL305BBR](#) [GRB136B05BB2](#) [GRB290AL105BRR](#) [GRB290AL405BBR](#)
[GRB290AL205BRR](#)