
 

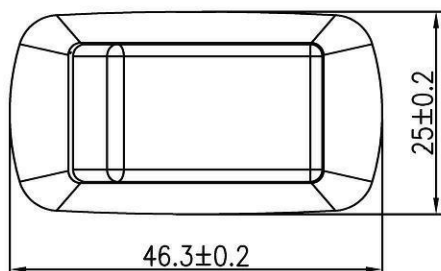


Rating	20A 125VAC 10A 25VAC 16A 125VAC 3/4HP 10A 277VAC 3/4HP	<div>Mounting Hole</div> <div></div>			<div>Circuit Diagram</div> <div></div>
					
	21A 14VDC				
Contact Resistance	50m ohm Max.				
Insulation Resistance	DC 500V 100M ohm Min.				
Dielectric Strength	AC 1500V 1 minute	Thickness(mm)	X(mm)	Y(mm)	
Operation Temperature	-20°~85°	0.75~1.25	21.2+0.1	36.6 ^{+0.2} ₋₀	
Switch Function	2P SPST ON-OFF	1.25~2.0		36.8 ^{+0.2} ₋₀	
		2.0~3.0		37.0 ^{+0.2} ₋₀	


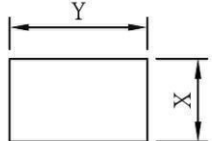



MATERIAL:


Frame: Nylon 66, Black

Actuator: Nylon 66 with 33%GF, Black

Water proof and dust proof to fit IP-56

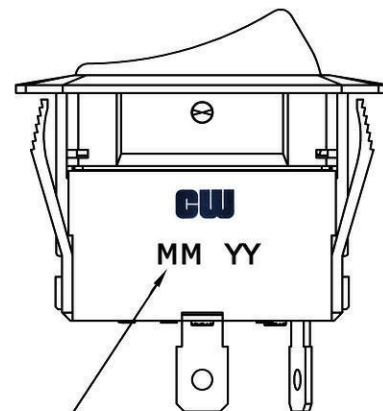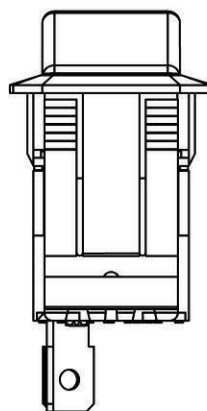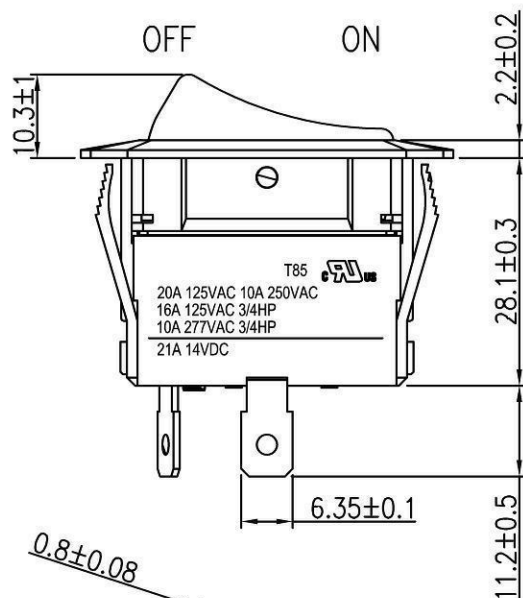

Date Code

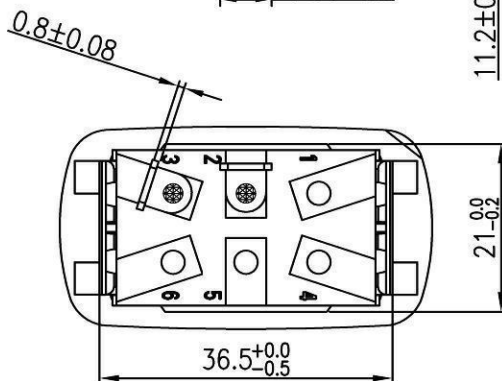

RoHS Compliant

CW INDUSTRIES
Southampton, Pa. 18966
Tel 215.355.7080/www.cwind.com

Date Drawn: 10/08/09

Rev. 1

Unit: mm

Checked By: GG

Title: **ROCKER SWITCH**

CW P/N: **GRB260A101BBNN**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CW Industries:](#)

[GRB260A101BBNN](#)