

SPECIFICATION:

Contact resistance: 20m ohm max. (initial)

Insulation resistance: 100M ohm min. (at 500V DC)

Dielectric strength: 1,500V AC 50/60 Hz for 1 minute

Service life: Mechanically: 100,000 operations min.

Electrically: 30,000 operations min.

Rating: 12A 125V AC / 250V AC






1/2 HP 125VAC / 1HP 250VAC / 5A 125VAC "L"

Function: OFF - ON SPST

KEYWAY
POSITION

Actuator: Brass / Dull Nickel Plated

Waterproof rating: IP68

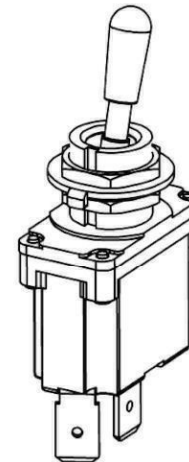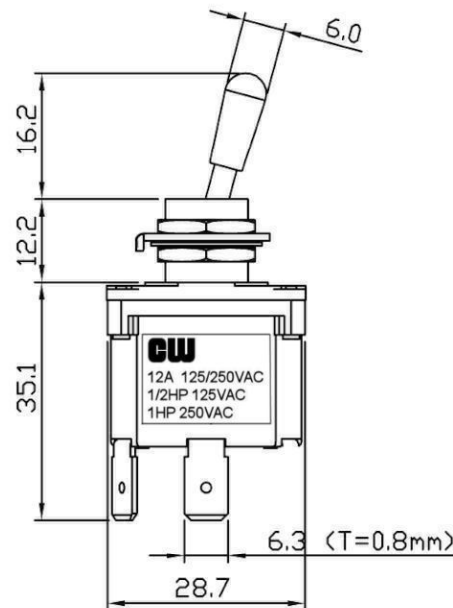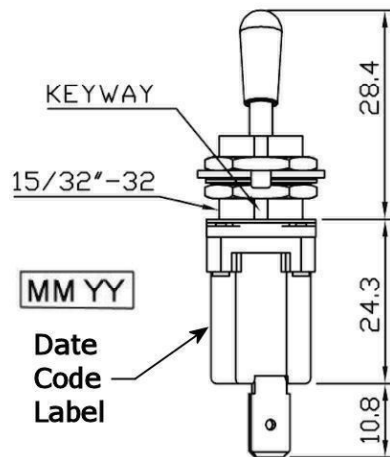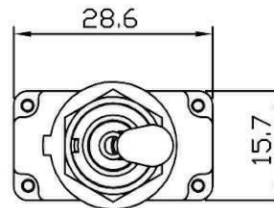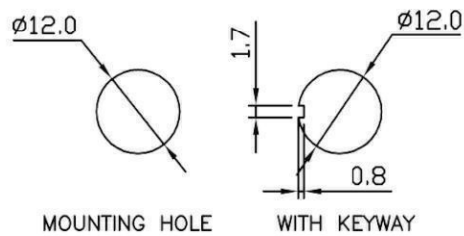

RoHS Compliant

CW INDUSTRIES
Southampton, Pa. 18966
Tel 215.355.7080/www.cwind.com

Date Drawn: 3-23-12

Rev. 0

Unit: mm

Checked By: *G. Gold*

Title:

TOGGLE SWITCH

CW P/N:

GTB2B12

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CW Industries:](#)

[GTB2B12](#)