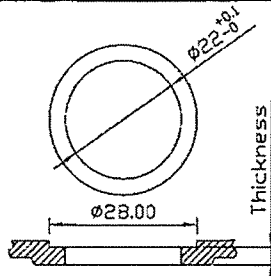
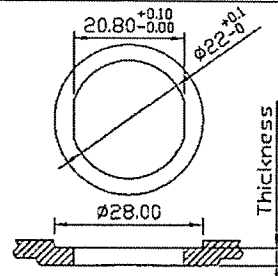


Rating	10A 14VDC	Mounting Hole	
Contact Resistance	50m ohm Max.		
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-25°C~85°C		
Switch Function	2P SPST OFF-(ON)		

( ) = Momentary Function

#### MATERIAL:

Frame: Black, Nylon 66 (94-V2)

Actuator: PC Clear (94-V2), For Color Ref. "X"  
in Actuator Color Chart and CW P/N.


Waterproof Rubber: Black, Silicone

Printed: None


Waterproof: IP65

Electrical life at full load: 20,000 cycles.

#### Circuit Diagram

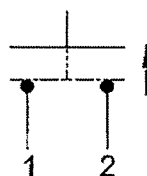

ACTUATOR COLOR	X
Amber	A
Black	B
Green	G
Red	R
Blue	U
White	W

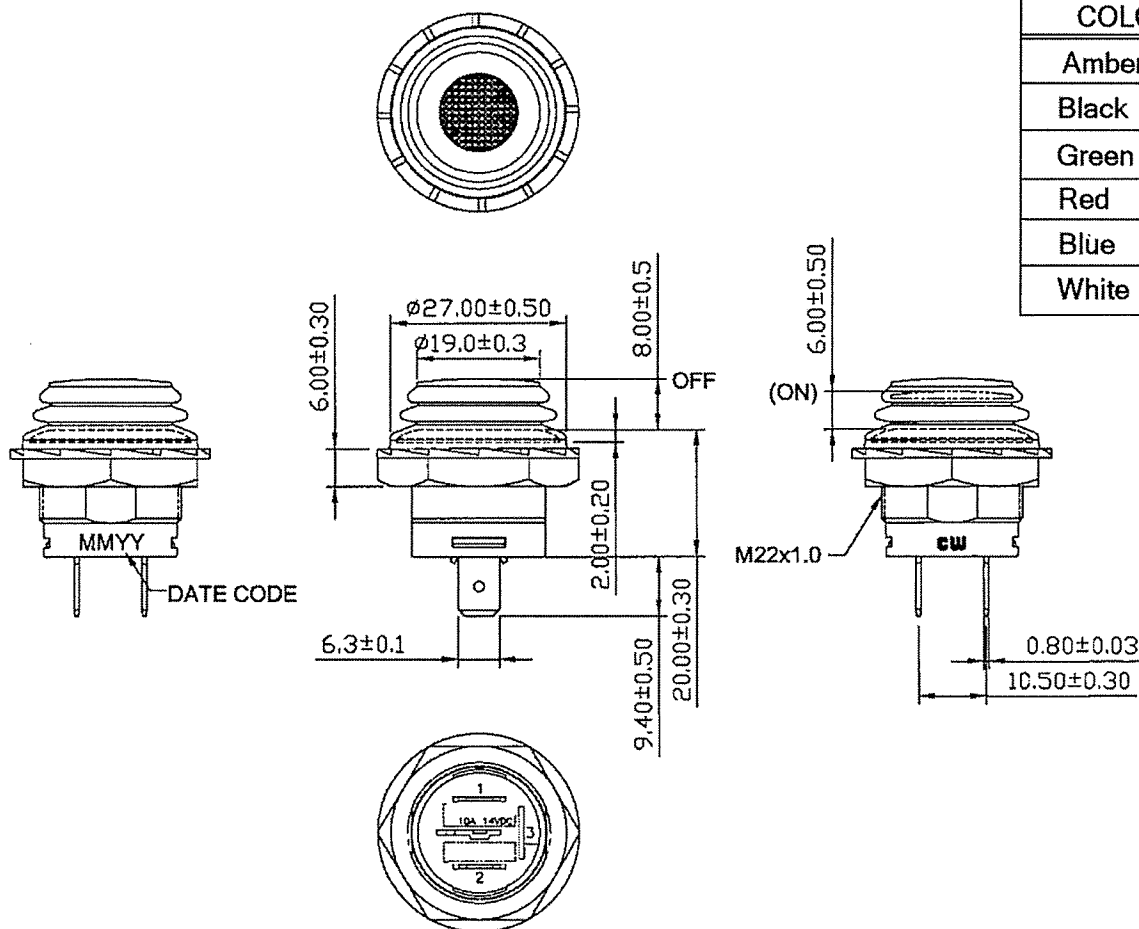

RoHS Compliant

**CW INDUSTRIES**  
Southampton, Pa. 18966  
Tel 215.355.7080/www.cwind.com

Date Drawn: 6-05-12

Rev. 0

Unit: mm

Checked By: *G. Gold*

Title:  
**PUSH BUTTON SWITCH**

CW P/N:  
**GPB553A201BX**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CW Industries:](#)

[GPB553A201BR](#)