


11 PHC




With Tube
For High Currents

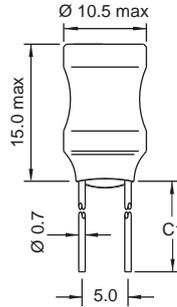

| Packaging | C1 |
|--------------------|----|
| Loose / Box [-50] | 10 |
| Taped / Reel [-51] | 25 |

(Pin Type Coils)

Pluggable Inductors

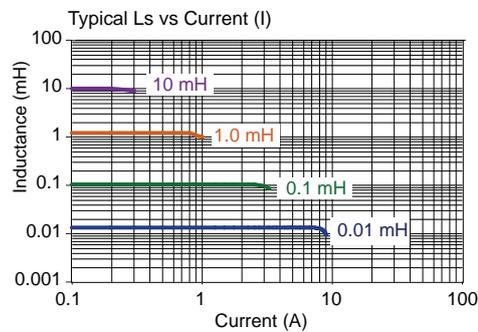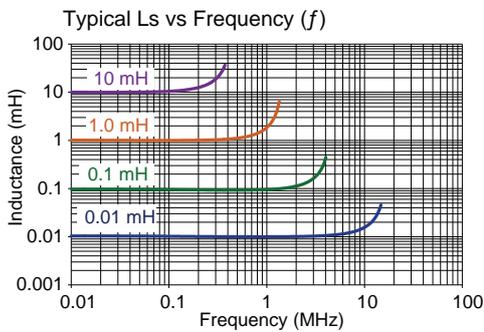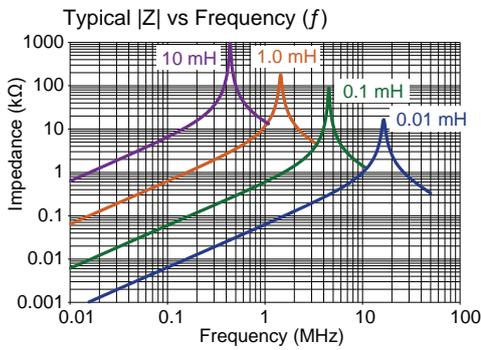

| Part No | Inductance L (mH) | f _L (MHz) | Tol ± (%) | DCR max (Ω) | Rated DC Current (A) | |
|---------------|----------------------|-------------------------|--------------|-------------------|----------------------|------------------|
| | | | | | I _{sat} | I _{max} |
| 11PHC-100K-YY | 0.01 | 0.02 | 10 | 0.03 | 6.66 | 4.07 |
| 11PHC-101K-YY | 0.10 | 0.02 | 10 | 0.16 | 2.47 | 1.84 |
| 11PHC-221K-YY | 0.22 | 0.02 | 10 | 0.37 | 1.68 | 1.00 |
| 11PHC-331K-YY | 0.33 | 0.02 | 10 | 0.53 | 1.42 | 0.97 |
| 11PHC-471K-YY | 0.47 | 0.02 | 10 | 0.76 | 1.17 | 0.72 |
| 11PHC-561K-YY | 0.56 | 0.02 | 10 | 0.83 | 1.10 | 0.74 |
| 11PHC-701K-YY | 0.70 | 0.02 | 10 | 1.27 | 0.96 | 0.56 |
| 11PHC-761K-YY | 0.76 | 0.02 | 10 | 1.35 | 0.96 | 0.54 |
| 11PHC-102K-YY | 1.00 | 0.02 | 10 | 1.60 | 0.85 | 0.53 |
| 11PHC-152K-YY | 1.50 | 0.02 | 10 | 2.33 | 0.50 | 0.60 |
| 11PHC-162K-YY | 1.60 | 0.02 | 10 | 2.50 | 0.70 | 0.50 |
| 11PHC-222K-YY | 2.20 | 0.02 | 10 | 3.70 | 0.50 | 0.34 |
| 11PHC-272K-YY | 2.70 | 0.02 | 10 | 4.14 | 0.47 | 0.33 |
| 11PHC-332K-YY | 3.30 | 0.02 | 10 | 5.51 | 0.42 | 0.27 |
| 11PHC-103K-YY | 10 | 0.02 | 10 | 15.78 | 0.26 | 0.15 |
| 11PHC-123K-YY | 12 | 0.02 | 10 | 21.85 | 0.23 | 0.13 |
| 11PHC-153K-YY | 15 | 0.02 | 10 | 28.75 | 0.19 | 0.12 |
| 11PHC-183K-YY | 18 | 0.02 | 10 | 32.20 | 0.20 | 0.12 |
| 11PHC-223K-YY | 22 | 0.02 | 10 | 43 | 0.16 | 0.10 |
| 11PHC-273K-YY | 27 | 0.02 | 10 | 47 | 0.14 | 0.10 |
| 11PHC-333K-YY | 33 | 0.02 | 10 | 77 | 0.12 | 0.08 |
| 11PHC-373K-YY | 37 | 0.02 | 10 | 82 | 0.11 | 0.08 |
| 11PHC-393K-YY | 39 | 0.02 | 10 | 84 | 0.12 | 0.08 |
| 11PHC-473K-YY | 47 | 0.02 | 10 | 97 | 0.09 | 0.07 |

Core Material: Ferrite

Revision date: 29 Aug 2022

SPQ:

| Packaging Form | Loose / Box | Taped / Reel |
|----------------|-------------|--------------|
| Radial | 250 [-50] | 500 [-51] |

- Remarks:
- Unlisted inductance values available upon request.
 - 5% tolerance available upon request.
 - Also available without tube.
 - Also available with shorter leads.