


Specification Sheet

Part Number: 111-01125

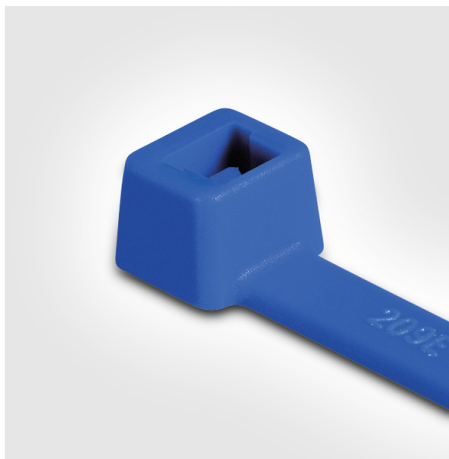

ETFE cable ties provide excellent resistance to chemicals, radiation, high temperatures and UV exposure.

Inside serrations allows for strong grip on cables and wire bundles.

Head design provides high tensile strength with very low insertion force.

High-Temp Cable Tie, 15" Long, UL Rated, 120lb Tensile Strength, ETFE, Blue, 50/pkg

Article Number	111-01125
----------------	-----------

Type	T120R
------	-------

Color	Blue (BU)
-------	-----------

Quantity Per	pack
--------------	------

Product Description	ETFE ties provide excellent protection against radiation, ultraviolet light, and a wide range of chemicals. They are also rated for low outgassing applications. HellermannTyton's ETFE ties come in a standard color of blue for easy identification. T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.
---------------------	---

Short Description	High-Temp Cable Tie, 15" Long, UL Rated, 120lb Tensile Strength, ETFE, Blue, 50/pkg
-------------------	---

Global Part Name	T120R-E/TFE-BU
------------------	----------------

Minimum Tensile Strength (Imperial)	120
-------------------------------------	-----

Minimum Tensile Strength (Metric)	535
-----------------------------------	-----

Length L (Imperial)	15.2
---------------------	------

Length L (Metric)	387.0
-------------------	-------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Variant	Inside Serrated
---------	-----------------

Width W (Imperial)	0.29
--------------------	------

Width W (Metric)	7.4
------------------	-----

Bundle Diameter Min (Imperial)	0.59
--------------------------------	------

Bundle Diameter Min (Metric)	15.0
------------------------------	------

Bundle Diameter Max (Imperial)	4.13
--------------------------------	------

Bundle Diameter Max (Metric)	105.0
------------------------------	-------

Thickness T (Imperial)	0.075
------------------------	-------

Thickness T (Metric)	1.9
Cable Tie Head Length (Imperial)	0.41
Cable Tie Head Width (Imperial)	0.50
Height H (Imperial)	0.29
Height H (Metric)	7.35
Material	Ethylentetrafluoroethylene (E/TFE)
Material Shortcut	E/TFE
Flammability	UL 94 V-0
UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-112°F to +338°F (-80°C to +170°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	UL ANSI/UL 1565 UL ANSI/UL 746B UL ANSI/UL 62275
UL Recognized (US)	Yes

Package Quantity (Imperial)	50
Package Quantity (Metric)	50
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)