


Specification Sheet

Part Number: 111-01611

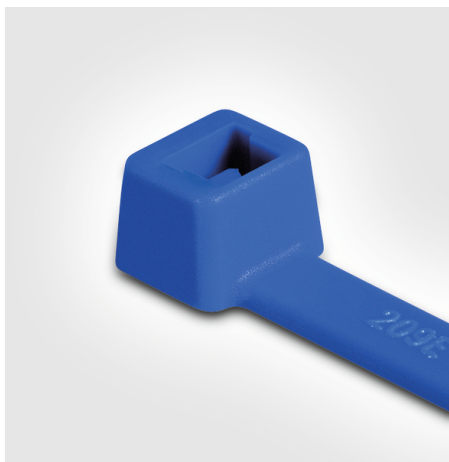

ETFE cable ties provide excellent resistance to chemicals, radiation, high temperatures and UV exposure.

Inside serrations allows for strong grip on cables and wire bundles.

Head design provides high tensile strength with very low insertion force.

Bent tail ensures a quick and simple installation.

High-Temp Cable Tie, 4" Long, UL Rated, 18lb Tensile Strength, ETFE, Blue, 1000/pkg

Article Number	111-01611
----------------	-----------

Type	T18R
------	------

Color	Blue (BU)
-------	-----------

Quantity Per	pack
--------------	------

Product Description	T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. The bent tail design allows quick and simple installations by hand. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.
---------------------	--

Short Description	High-Temp Cable Tie, 4" Long, UL Rated, 18lb Tensile Strength, ETFE, Blue, 1000/pkg
-------------------	---

Global Part Name	T18R-E/TFE-BU
------------------	---------------

Minimum Tensile Strength (Imperial)	18
-------------------------------------	----

Minimum Tensile Strength (Metric)	80
-----------------------------------	----

Length L (Imperial)	3.94
---------------------	------

Length L (Metric)	100.0
-------------------	-------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Variant	Inside Serrated
---------	-----------------

Width W (Imperial)	0.10
--------------------	------

Width W (Metric)	2.5
------------------	-----

Bundle Diameter Min (Imperial)	0.2
--------------------------------	-----

Bundle Diameter Min (Metric)	5.0
------------------------------	-----

Bundle Diameter Max (Imperial)	0.87
--------------------------------	------

Bundle Diameter Max (Metric)	22.0
------------------------------	------

Thickness T (Metric)	1.2
----------------------	-----

Cable Tie Head Length (Imperial)	0.19
Cable Tie Head Width (Imperial)	0.18
Height H (Imperial)	0.15
Height H (Metric)	3.7
Material	Ethylentetrafluoroethylene (E/TFE)
Material Shortcut	E/TFE
Flammability	UL 94 V-0
UV Resistant (Yes/No)	Yes
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-112°F to +338°F (-80°C to +170°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Package Quantity (Imperial)	1000
Package Quantity (Metric)	1000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)