


Specification Sheet

Part Number: 118-00116

Extreme temperature range for excellent performance in a range of environments.

Low-profile, contoured head takes up less space and protects sensitive wires.

Delivers the performance of a metal tie with the ease of use of plastic.

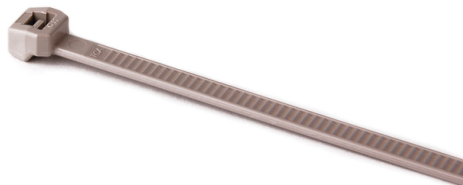

High-Temp Cable Tie, 9.8" Long, 67lb Tensile Strength, PEEK, Beige, 100/pkg

Article Number	118-00116
----------------	-----------

Type	PT3B
------	------

Color	Beige (BGE)
-------	-------------

Quantity Per	pack
--------------	------

Product Description	PEEK Ties withstand temperatures from -67 to 464° F and provide excellent resistance to chemicals, acids, radiation and abrasion. The low-profile, contoured head takes up less space and protects sensitive wires running adjacent to it.
---------------------	--

Short Description	High-Temp Cable Tie, 9.8" Long, 67lb Tensile Strength, PEEK, Beige, 100/pkg
-------------------	---

Global Part Name	PT3B-PEEK-BGE
------------------	---------------

Minimum Tensile Strength (Imperial)	67
Minimum Tensile Strength (Metric)	300
Length L (Imperial)	9.8
Length L (Metric)	250.0
Identification Plate Position	none
Releasable Closure	No
Tie Closure	plastic pawl
Variant	Outside Serrated
Width W (Imperial)	0.18
Width W (Metric)	4.65
Bundle Diameter Min (Imperial)	0.16
Bundle Diameter Min (Metric)	4.0
Bundle Diameter Max (Imperial)	2.56
Bundle Diameter Max (Metric)	65.0
Thickness T (Metric)	1.5

Material	Polyetheretherketone (PEEK)
Material Shortcut	PEEK
Flammability	UL 94 V-0 (3 mm)
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-67°F to +464°F (-55°C to +240°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
 Phone: (800) 537-1512 | Email: corp@htamericas.com