


Specification Sheet

Part Number: 157-00328

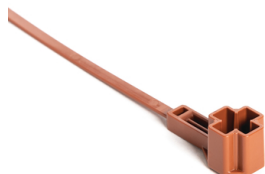

Offset design positions bundles away from obstructions, heat or sources of abrasion.

Four-pawl, three-tooth design delivers outstanding stud retention to keep bundles secure.

PA46 material option allows use in high-heat applications.

Offset M8 Stud Mount Tie, 7.5" Tie, 25.5 mm Offset, 50lb Tensile Strength, PA46, Brown, 1500/pkg

Article Number	157-00328
----------------	-----------

Type	T50ROSM8SMSO25
------	----------------

Color	Brown (BN)
-------	------------

Quantity Per	pack
--------------	------

Product Description	This mount features an offset design, which positions bundles away from obstructions, heat or sources of abrasion. With their low insertion force and high extraction performance, HellermannTyton mounting ties offer the ideal combination of high-grade materials and superior design to suit the mounting and bundling needs of complex applications. Available in standard and high-heat material options.
---------------------	---

Short Description	Offset M8 Stud Mount Tie, 7.5" Tie, 25.5 mm Offset, 50lb Tensile Strength, PA46, Brown, 1500/pkg
-------------------	--

Global Part Name	T50ROSM8SMSO25-PA46-BN
------------------	------------------------

Minimum Tensile Strength (Imperial)	50
-------------------------------------	----

Minimum Tensile Strength (Metric)	223
-----------------------------------	-----

Length L (Imperial)	8.9
---------------------	-----

Length L (Metric)	226.14
-------------------	--------

Offset Length (Imperial)	1.0
--------------------------	-----

Offset Length (Metric)	25.5
------------------------	------

Fixation Method	Stud Mount
-----------------	------------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Width W (Imperial)	0.70
--------------------	------

Width W (Metric)	17.75
------------------	-------

Bundle Diameter Min (Imperial)	0.08
--------------------------------	------

Bundle Diameter Min (Metric)	2.0
------------------------------	-----

Bundle Diameter Max (Imperial)	1.97
--------------------------------	------

Bundle Diameter Max (Metric)	50.0
Cable Ties	157-00328
Height H (Imperial)	0.59
Height H (Metric)	15.0
Mounting Hole Diameter D (Imperial)	0.31 x 0.05 "
Mounting Hole Diameter D (Metric)	M8 x 1.25
Stud Diameter (Metric)	8.0 mm
Material	Polyamide 4.6 (PA46)
Material Shortcut	PA46
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	1500

Package Quantity (Metric)	1500
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)