


Specification Sheet

Part Number: 157-00341

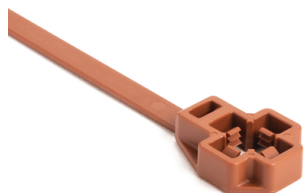

Low-profile head allows mounts to stack, providing more mounting versatility from a single stud.

Four-pawl, three-tooth design delivers outstanding stud retention to keep bundles secure.

PA46 material option allows use in high-heat applications.

Low Profile M8 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 2000/pkg

Article Number	157-00341
----------------	-----------

Type	T80ROSLPSB8U
------	--------------

Color	Brown (BN)
-------	------------

Quantity Per	pack
--------------	------

Product Description	Mount features a low-profile head, allowing multiple tie mounts to be stacked on a single bolt and providing space savings in tight areas. With their low insertion force and high extraction performance, HellermannTyton mounting ties offer the ideal combination of high-grade materials and superior design to suit the mounting and bundling needs of complex applications. Available in standard and high-heat material options.
---------------------	---

Short Description	Low Profile M8 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 2000/pkg
-------------------	---

Global Part Name	T80ROSLPSB8U-PA46-BN
------------------	----------------------

Minimum Tensile Strength (Imperial)	80
-------------------------------------	----

Minimum Tensile Strength (Metric)	355
-----------------------------------	-----

Length L (Imperial)	8.3
---------------------	-----

Length L (Metric)	212.0
-------------------	-------

Fixation Method	Stud Mount
-----------------	------------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Width W (Imperial)	0.70
--------------------	------

Width W (Metric)	17.75
------------------	-------

Bundle Diameter Min (Imperial)	0.14
--------------------------------	------

Bundle Diameter Min (Metric)	3.5
------------------------------	-----

Bundle Diameter Max (Imperial)	1.97
--------------------------------	------

Bundle Diameter Max (Metric)	50.0
------------------------------	------

Cable Ties	157-00341
------------	-----------

Height H (Imperial)	0.25
Height H (Metric)	6.30
Mounting Hole Diameter D (Imperial)	0.31 x 0.05
Mounting Hole Diameter D (Metric)	M8 x 1.25
Stud Diameter (Metric)	8.0 mm
Stud Diameter (Imperial)	0.31
Material	Polyamide 4.6 (PA46)
Material Shortcut	PA46
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes

Package Quantity (Imperial)	2000
Package Quantity (Metric)	2000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)