


Specification Sheet

Part Number: 157-00343

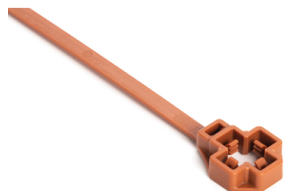

Low-profile head allows mounts to stack, providing more mounting versatility from a single stud.

Four-pawl, three-tooth design delivers outstanding stud retention to keep bundles secure.

PA46 material option allows use in high-heat applications.

Low Profile M10 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 3500/pkg

Article Number	157-00343
----------------	-----------

Type	T80ROSLPSB10U
------	---------------

Color	Brown (BN)
-------	------------

Quantity Per	pack
--------------	------

Product Description	One-piece mounting ties offer a complete solution by both bundling cable and at the same time providing a mounting solution. HellermannTyton's one-piece mounting ties offer the ideal combination of high specification materials and superior design to suit the mounting and bundling needs of complex applications.
---------------------	---

Short Description	Low Profile M10 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 3500/pkg
-------------------	--

Global Part Name	T80ROSLPSB10U-PA46-BN
------------------	-----------------------

Minimum Tensile Strength (Imperial)	80
-------------------------------------	----

Minimum Tensile Strength (Metric)	355
-----------------------------------	-----

Length L (Imperial)	8.5
---------------------	-----

Length L (Metric)	215.9
-------------------	-------

Fixation Method	Stud Mount
-----------------	------------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Width W (Imperial)	0.82
--------------------	------

Width W (Metric)	20.8
------------------	------

Bundle Diameter Min (Imperial)	0.14
--------------------------------	------

Bundle Diameter Min (Metric)	3.5
------------------------------	-----

Bundle Diameter Max (Imperial)	1.97
--------------------------------	------

Bundle Diameter Max (Metric)	50.0
------------------------------	------

Cable Ties	157-00343
------------	-----------

Height H (Imperial)	0.28
Height H (Metric)	7.0
Mounting Hole Diameter D (Imperial)	0.39 x 0.06 "
Mounting Hole Diameter D (Metric)	M10 x 1.5
Stud Diameter (Metric)	10.0 mm
Material	Polyamide 4.6 (PA46)
Material Shortcut	PA46
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	3500

Package Quantity (Metric)	3500
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)