


Specification Sheet

Part Number: 161-46000

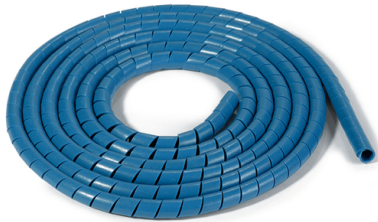

Industry standard blue color assists with visual detection and reduces the risk of contamination.

High stainless-steel content is both detectable and corrosion resistant.

Open design accommodates breakouts at any point along the bundle.

Spiral design makes it suitable for retro-fitting.

Spiralwrap Metal-Content, 0.06" Diameter, PE/SS, Blue, 98 ft/roll

Article Number	161-46000
----------------	-----------

Type	SBPEMC1.5
------	-----------

Color	Blue (BU)
-------	-----------

Quantity Per	pack
--------------	------

Product Description	SBPEMC provides flexible, durable cable and hose protection. It is ideal for food-processing machines and related environments. Protects against abrasion, making it appropriate for applications where movement is an issue.
---------------------	---

Short Description	Spiralwrap Metal-Content, 0.06" Diameter, PE/SS, Blue, 98 ft/roll
-------------------	---

Global Part Name	SBPEMC1.5-PE/SS-BU
------------------	--------------------

Length L (Metric)	30
Variant	Spiral Binding
Bundle Diameter Min (Imperial)	0.06
Bundle Diameter Min (Metric)	1.6
Bundle Diameter Max (Imperial)	0.31
Bundle Diameter Max (Metric)	8
Diameter D (Imperial)	0.06
Diameter D (Metric)	1.5
Nominal Diameter (Imperial)	0.06
Nominal Diameter (Metric)	1.5
Wall Thickness WT (Imperial)	0.031
Wall Thickness WT (Metric)	0.8
Material	Stainless Steel (SS) Polyethylene (PE)
Material Shortcut	SS PE
Flammability	UL 94 HB

Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-76°F to +176°F (-60°C to +80°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	98.43
Package Quantity (Metric)	30
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)