


Specification Sheet

Part Number: 161-46200

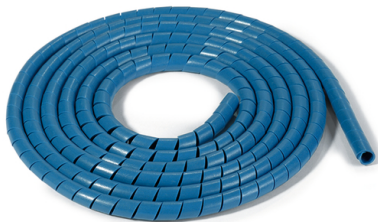

Industry standard blue color assists with visual detection and reduces the risk of contamination.

High stainless-steel content is both detectable and corrosion resistant.

Open design accommodates breakouts at any point along the bundle.

Spiral design makes it suitable for retro-fitting.

Spiralwrap Metal-Content, 0.35" Diameter, PE/SS, Blue, 98 ft/roll

Article Number	161-46200
----------------	-----------

Type	SBPEMC9
------	---------

Color	Blue (BU)
-------	-----------

Quantity Per	pack
--------------	------

Product Description	SBPEMC provides flexible, durable cable and hose protection. It is ideal for food-processing machines and related environments. Protects against abrasion, making it appropriate for applications where movement is an issue.
---------------------	---

Short Description	Spiralwrap Metal-Content, 0.35" Diameter, PE/SS, Blue, 98 ft/roll
-------------------	---

Global Part Name	SBPEMC9-PE/SS-BU
------------------	------------------

Variant	Spiral Binding
Bundle Diameter Min (Imperial)	0.39
Bundle Diameter Min (Metric)	10
Bundle Diameter Max (Imperial)	3.94
Bundle Diameter Max (Metric)	100
Diameter D (Imperial)	0.35
Diameter D (Metric)	9
Nominal Diameter (Imperial)	0.38
Nominal Diameter (Metric)	9
Wall Thickness WT (Imperial)	0.055
Wall Thickness WT (Metric)	1.4
Material	Stainless Steel (SS) Polyethylene (PE)
Material Shortcut	PE SS
Flammability	UL 94 HB
Halogen Free	Yes

UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-76°F to +176°F (-60°C to +80°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	98.43
Package Quantity (Metric)	30
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)