

Specification Sheet


Part Number: CTN140STDUNSLIT

Durable tubing provides protection of wire harness from friction, vibration, fraying and puncture

Tubing protects cables and wires against automotive fluids, vibration wear

Weather resistant material provides protection against water, snow, ice, and the effects of heat, cold, and sunlight

Nylon material is formulated to withstand high temperatures

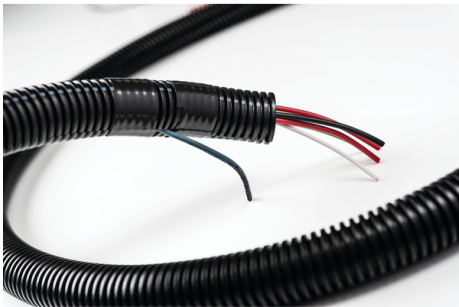

Article Number

169-60029

Type

CTN140UNSLIT

Color

Black with Gray Stripe (BKSTGY)

Quantity Per

carton

Product Description

HellermannTyton's Convoluted Tubing, also known as Loom Tubing, provides an efficient method of routing and protecting wire harness assemblies, while reducing the chance of installation damage. It can also serve to protect valuable hoses and cables. Convoluted tubing offers excellent protection against vibration wear, water, snow, ice and the effects of heat, cold and sunlight on cables and wires.

Short Description

Convoluted Tubing, Unslit, 0.25" Dia, PA6, Black with Gray Stripe, 2500 ft/ctn

Global Part Name	CTN140UNSLIT-PA6-BK
------------------	---------------------

Length L (Imperial)	2500.0
---------------------	--------

Length L (Metric)	762.0
-------------------	-------

Variant	Unslit
---------	--------

Inner Diameter D (Imperial)	0.276
-----------------------------	-------

Inner Diameter D (Metric)	7.01
---------------------------	------

Diameter D (Imperial)	0.398
-----------------------	-------

Diameter D (Metric)	10.11
---------------------	-------

Outside Diameter OD (Imperial)	0.398
--------------------------------	-------

Outside Diameter OD (Metric)	10.11
------------------------------	-------

Nominal Diameter (Imperial)	0.25
-----------------------------	------

Nominal Diameter (Metric)	6.35
---------------------------	------

Wall Thickness WT (Imperial)	0.004
------------------------------	-------

Wall Thickness WT (Metric)	0.102
----------------------------	-------

Material	Polyamide 6 (PA6)
----------	-------------------

Material Shortcut	PA6
Flammability	UL 94 HB
Halogen Free	No
UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +257°F (-40°C to +125°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	2500
Package Quantity (Metric)	762.0
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
 Phone: (800) 537-1512 | Email: corp@htamericas.com