


Specification Sheet

Part Number: 181-00657

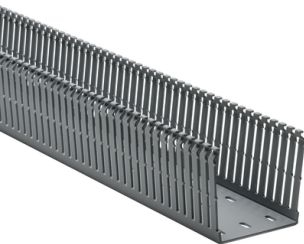

- Narrow fingers reduce fanning of wires to terminal blocks, providing a neater appearance.
- Each finger features a double restriction to hold wires in the bottom portion of the duct, simplifying installation.
- Mounting holes are uniform in size to those in slotted and solid wall duct but are provided every two inches to accommodate compact designs and provide ease of installation.
- Nonpermanent adhesive allows repositioning prior to final installation.

High Density Slotted Wall Wiring Duct, 3" x 3", Adhesive, PVC, Gray, 120ft/Carton

Article Number	181-00657
Type	SLHDA3X3
Color	Gray (GY)
Quantity Per	carton
Product Description	HellermannTyton High-Density Slotted Wall Wiring Duct features narrow fingers equaling a 2-to-1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

Short Description	High Density Slotted Wall Wiring Duct, 3" x 3", Adhesive, PVC, Gray, 120ft/Carton
Global Part Name	SLHDA3X3-PVC-GY
Length L (Imperial)	6.0
Length L (Metric)	1.83
Fixation Method	Adhesive
Width W (Imperial)	3.0
Width W (Metric)	76.2
Height H (Imperial)	3.07
Height H (Metric)	77.9
Mounting Hole Centers (Imperial)	2.0
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Halogen Free	No
UV Resistant (Yes/No)	No

Use Conditions	For Indoor Use Only
Operating Temperature	+122°F (+50°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Certification/Specification	EN 50085-2-3_1A UL EN 50085-1:2005 + A1:2013 CSA
UL Recognized (US)	Yes
Package Quantity (Imperial)	120.0
Package Quantity (Metric)	36.58
Customs Number	3925900000

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)