


Specification Sheet

Part Number: 181-13009

- Strong fingers prevent unintended breaking.
- Fingers are easily deflected outward, allowing easier positioning of the wires.
- Restricted opening prevents unintended removal of wires and permits any individual wire to be traced without disconnection.
- Nonpermanent adhesive allows repositioning prior to final installation.
- Optional covers snap on and off easily, and their nonslip lining ensures they stay in place even under vibration.

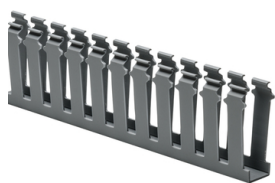

Slotted Wall Wiring Duct, 1" x 3", Adhesive, PVC, Gray, 30ft/Box

|                     |                                                                                                                                                                                                                                                                                                                                                                                                                             |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Article Number      | 181-13009                                                                                                                                                                                                                                                                                                                                                                                                                   |
| Type                | SLA1X3                                                                                                                                                                                                                                                                                                                                                                                                                      |
| Color               | Gray (GY)                                                                                                                                                                                                                                                                                                                                                                                                                   |
| Quantity Per        | pack                                                                                                                                                                                                                                                                                                                                                                                                                        |
| Product Description | HellermannTyton Slotted Wall Duct features breakaway fingers that provide additional access for wire leads. Each section of the duct is provided with two score lines. The upper score line is used to break away fingers when a wider opening is required. The lower score line allows the sidewall to be smoothly cut for joints and Ts. Pressure-sensitive, rubber-based adhesive backing aids in temporary positioning. |

|                   |                                                                  |
|-------------------|------------------------------------------------------------------|
| Short Description | Slotted Wall Wiring Duct, 1" x 3", Adhesive, PVC, Gray, 30ft/Box |
|-------------------|------------------------------------------------------------------|

|                  |               |
|------------------|---------------|
| Global Part Name | SLA1X3-PVC-GY |
|------------------|---------------|

|                     |     |
|---------------------|-----|
| Length L (Imperial) | 6.0 |
|---------------------|-----|

|                   |      |
|-------------------|------|
| Length L (Metric) | 1.83 |
|-------------------|------|

|                    |     |
|--------------------|-----|
| Width W (Imperial) | 1.0 |
|--------------------|-----|

|                  |      |
|------------------|------|
| Width W (Metric) | 25.4 |
|------------------|------|

|                     |      |
|---------------------|------|
| Height H (Imperial) | 3.07 |
|---------------------|------|

|                   |      |
|-------------------|------|
| Height H (Metric) | 77.9 |
|-------------------|------|

|                                  |     |
|----------------------------------|-----|
| Mounting Hole Centers (Imperial) | 4.0 |
|----------------------------------|-----|

|          |                         |
|----------|-------------------------|
| Material | Polyvinylchloride (PVC) |
|----------|-------------------------|

|                   |     |
|-------------------|-----|
| Material Shortcut | PVC |
|-------------------|-----|

|              |    |
|--------------|----|
| Halogen Free | No |
|--------------|----|

|                       |    |
|-----------------------|----|
| UV Resistant (Yes/No) | No |
|-----------------------|----|

|                |                     |
|----------------|---------------------|
| Use Conditions | For Indoor Use Only |
|----------------|---------------------|

|                       |                |
|-----------------------|----------------|
| Operating Temperature | +122°F (+50°C) |
|-----------------------|----------------|

|                              |                                                  |
|------------------------------|--------------------------------------------------|
| Reach Compliant (Article 33) | No                                               |
| ROHS Compliant               | Yes                                              |
| Certification/Specification  | EN 50085-1:2005 + A1:2013 EN 50085-2-3_1A CSA UL |
| UL Recognized (US)           | Yes                                              |
| Package Quantity (Imperial)  | 30.0                                             |
| Package Quantity (Metric)    | 9.14                                             |
| Customs Number               | 3925900000                                       |

7930 N. Faulkner Road, Milwaukee, WI 53224  
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.  
[Contact Us](#)   [RoHS/WEEE Compliance](#)   [Disclaimer](#)   [Terms and Conditions](#)