


Specification Sheet

Part Number: 181-23035

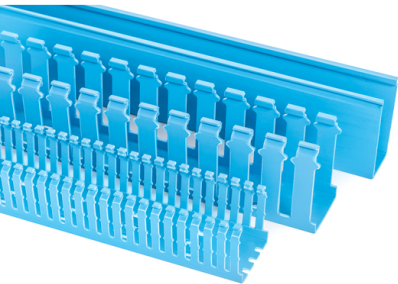

- Strong fingers prevent unwanted breaking.
- Fingers are easily deflected outward, allowing ready positioning of the wires within the slotted wall duct.
- Restricted opening design in the finger of the duct helps keep wires in place.
- Restricted opening prevents unintended removal of wires and permits any individual wire to be traced without disconnection.
- Supplied with mounting holes to streamline installation.
- Optional covers enhance protection and appearance.

Slotted Wall Wiring Duct, 2" x 5", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/carton

|                |                      |
|----------------|----------------------|
| Article Number | 181-23035            |
| Type           | SL2X5                |
| Color          | Intrinsic Blue (IBU) |
| Quantity Per   | carton               |

|                                  |                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |
|----------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product Description              | <p>Manufactured from the same PVC material as standard Pro-Duct colors, HellermannTyton also offers an intrinsic blue color option. The intrinsic blue color indicates that the wiring contained in the duct runs to intrinsically safe components in the control panel. Pro-Duct slotted wall wiring duct features break-away fingers which provide additional access for wire leads. Each section of the duct is provided with two score lines. The upper score line is used to break away fingers when a greater opening is required. The lower score line allows the sidewall to be smoothly cut for joints and Ts.</p> |
| Short Description                | Slotted Wall Wiring Duct, 2" x 5", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/carton                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                         |
| Global Part Name                 | SL2X5-PVC-BU                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                |
| Length L (Imperial)              | 6.0                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                         |
| Length L (Metric)                | 1.83                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                        |
| Width W (Imperial)               | 2.0                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                         |
| Width W (Metric)                 | 50.8                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                        |
| Height H (Imperial)              | 5.07                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                        |
| Height H (Metric)                | 128.80                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                      |
| Mounting Hole Centers (Imperial) | 4.0                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                         |
| Material                         | Polyvinylchloride (PVC)                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                     |
| Material Shortcut                | PVC                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                         |

|                              |                                                  |
|------------------------------|--------------------------------------------------|
| Halogen Free                 | No                                               |
| UV Resistant (Yes/No)        | No                                               |
| Use Conditions               | For Indoor Use Only                              |
| Operating Temperature        | +122°F (+50°C)                                   |
| Reach Compliant (Article 33) | No                                               |
| ROHS Compliant               | Yes                                              |
| Certification/Specification  | UL CSA EN 50085-2-3_1A EN 50085-1:2005 + A1:2013 |
| UL Recognized (US)           | Yes                                              |
| Package Quantity (Imperial)  | 120.0                                            |
| Package Quantity (Metric)    | 36.58                                            |
| Customs Number               | 3925900000                                       |

7930 N. Faulkner Road, Milwaukee, WI 53224  
 Phone: (800) 537-1512 | Email: corp@htamericas.com