


Specification Sheet

Part Number: FPB

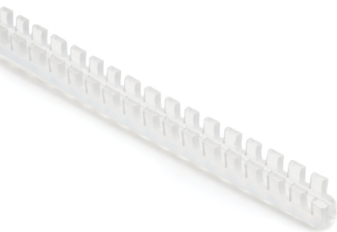

Can be cut to length with scissors, eliminating waste and keeping stock to a minimum.

Available in 9 sizes, for thicknesses from .016" to .512", insuring proper fit.

Grommet, Panel Thickness 0.051"-0.083", PE, Natural, 82ft/pkg

Article Number	251-10209
Type	G51PB
Color	Natural (NA)
Quantity Per	pack
Product Description	HellermannTyton's Flexiform grommet is a unique, continuous wire protection product which fits easily in all shapes and sizes of holes without the aid of tools or adhesives. Flexiform grommet can be used on any type of material including wood, steel, aluminum, plexiglass, and glass.
Short Description	Grommet, Panel Thickness 0.051"-0.083", PE, Natural, 82ft/pkg
Global Part Name	G51PB-PE-NA

Length L (Imperial)	82.0
---------------------	------

Variant	Open
---------	------

Width W (Imperial)	0.181
--------------------	-------

Width W (Metric)	4.6
------------------	-----

Height H (Imperial)	0.169
---------------------	-------

Height H (Metric)	4.3
-------------------	-----

Panel Thickness Min (Imperial)	0.05
--------------------------------	------

Panel Thickness Max (Imperial)	0.08
--------------------------------	------

Panel Thickness Min (Metric)	1.3
------------------------------	-----

Panel Thickness Max (Metric)	2.1
------------------------------	-----

Material	Polyethylene (PE)
----------	-------------------

Material Shortcut	PE
-------------------	----

Flammability	UL 94 HB
--------------	----------

Halogen Free	Yes
--------------	-----

UV Resistant (Yes/No)	No
-----------------------	----

Use Conditions	For Indoor Use Only
Operating Temperature	-22°F to +176°F (-30°C to +80°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	82
Package Quantity (Metric)	25
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)