


Specification Sheet

Part Number: 544-20000

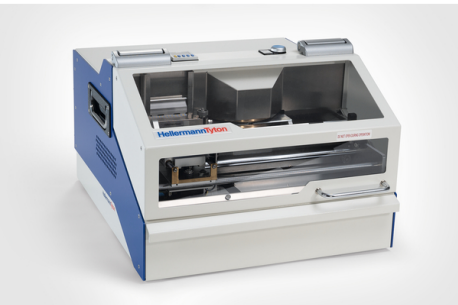

- Built in storage tray for safe storage of all printing components.
- Functions with TagPrint® Pro labeling software for easy label design.
- Tested to over 1.5 million strikes without maintenance for reliable embossing.
- Fast embossing speed for high volume marker production.

M-BOSS Compact Stainless Steel Embosser, Blue, 1/Box

Article Number	544-20000
Type	M-BOSS Compact
Color	Blue (BU) White (WH)
Quantity Per	pack
Product Description	M-BOSS Compact is a quiet, easy-to-use metal plate embossing printer with a small production footprint. It is simple to install and operate, requiring just a standard electrical supply and a PC. Marker plates are attached to pipes and cables using 4.6mm width MBT cable ties and a MK9SST hand tool.
Short Description	M-BOSS Compact Stainless Steel Embosser, Blue, 1/Box
Global Part Name	M-BOSS Compact-MET-BU/WH

Length L (Imperial)	19.0
Length L (Metric)	558
Width W (Imperial)	18.89
Width W (Metric)	480
Cycle Time	1 second per character
Height H (Imperial)	13.89
Height H (Metric)	355
Depth D (Imperial)	22.44
Depth D (Metric)	570
Diameter D (Metric)	370
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Power Supply	AC 110V-240V, 45/65 Hz, 1.5A-3A
Material	Metal (MET)
Material Shortcut	MET

Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Certification/Specification	DEKRA EN 60204-1:2006 CE 2006/42/EG DEKRA EN ISO 12100:2010
Package Quantity (Imperial)	1
Package Quantity (Metric)	1
Customs Number	8463900080

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)