

Specification Sheet


Part Number: 596-00654

Made with UV-stable inks and materials for durability and weather resistance.

Reflective properties to meet applicable NEC code requirements for reflective identification.

Supplied with an aggressive adhesive to ensure long life.

Meets NEC & IFC standards for printed text, character height, color and outdoor UV stability to pass inspections.

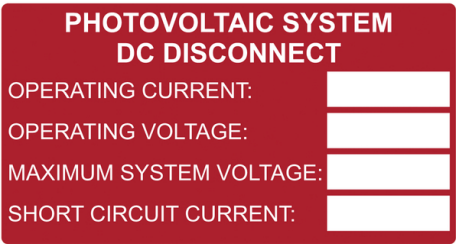

Solar Label, Printable, DC Rating, 3.75" x 2.0", PET, Red, 50/roll

Article Number	596-00654
Type	DCRATING-1
Color	Red (RD)
Quantity Per	pack
Product Description	Designed in a one-across landscape format to fit into the compact TT130SMC thermal transfer printer, these labels allow for code-compliant marking of variable information including disconnecting means, breaker series and voltage data. Made with cross-laminated UV stable materials, labels are ideal for use in solar installation applications. Use with the TT130SMC or any HellermannTyton thermal transfer printer.

Short Description	Solar Label, Printable, DC Rating, 3.75" x 2.0", PET, Red, 50/roll
-------------------	--

Global Part Name	DCRATING-1-840/281-RD
------------------	-----------------------

Width W (Imperial)	2.0
--------------------	-----

Width W (Metric)	50.8
------------------	------

Thickness T (Metric)	64.0
----------------------	------

Height H (Imperial)	3.75
---------------------	------

Height H (Metric)	95.25
-------------------	-------

Material	Type 840/281, Polyester, UV-stabilized, clear polyester laminate (840/281)
----------	--

Material Shortcut	840/281
-------------------	---------

Adhesive	Acrylic
----------	---------

Halogen Free	No
--------------	----

UV Resistant (Yes/No)	Yes
-----------------------	-----

Use Conditions	For Indoor and Outdoor Use
----------------	----------------------------

Adhesive Operating Temperature	-40°F to +302°F (-40°C to +150°C)
--------------------------------	-----------------------------------

Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	UL 969
UL Recognized (US)	Yes
Package Quantity (Imperial)	50
Package Quantity (Metric)	50
Customs Number	3919102055
Labels per Column	1
Labels per Row	1

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com