

Stainless steel pre-embossed marking system, manual


Hellermark SSC

Hellermark SSM

Hellermark is used in the rail, marine, offshore, petrochemical, food and construction industries, for the identification of cables, pipes and other equipment in harsh environments.

Features and benefits

- Stainless steel pre-embossed marker tiles
- Use in harsh and hazardous conditions
- Made of grade SS316 stainless steel for ideal use in aggressive environments
- Insert marker tiles (SSM) into fitting carrier (SSC) and close ends with pliers
- Fasten carriers using stainless steel cable ties with max. strap width of 8 mm
- Carrier can be riveted or screw-fixed using two 3 mm holes at each end

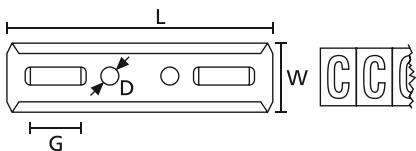

Hellermark SSC and SSM.

TYPE	Marking Text	Pack Cont.	Article-No.
SSM	+	200 pcs.	540-01700
	-	200 pcs.	540-01703
	,	200 pcs.	540-01702
	.	200 pcs.	540-01701
	/	200 pcs.	540-01720
	0	200 pcs.	540-01600
	1	200 pcs.	540-01610
	2	200 pcs.	540-01620
	3	200 pcs.	540-01630
	4	200 pcs.	540-01640
	5	200 pcs.	540-01650
	6	200 pcs.	540-01660
	7	200 pcs.	540-01670
	8	200 pcs.	540-01680
	9	200 pcs.	540-01690
	⊥	200 pcs.	540-01730

TYPE	Marking Text	Pack Cont.	Article-No.
SSM	A	200 pcs.	540-01010
	B	200 pcs.	540-01020
	C	200 pcs.	540-01030
	D	200 pcs.	540-01040
	E	200 pcs.	540-01050
	F	200 pcs.	540-01060
	G	200 pcs.	540-01070
	H	200 pcs.	540-01080
	I	200 pcs.	540-01090
	J	200 pcs.	540-01100
	K	200 pcs.	540-01110
	L	200 pcs.	540-01120
	M	200 pcs.	540-01130
	N	200 pcs.	540-01140
	O	200 pcs.	540-01150
	P	200 pcs.	540-01160
	Q	200 pcs.	540-01170
	R	200 pcs.	540-01180
	S	200 pcs.	540-01190
	T	200 pcs.	540-01200
	U	200 pcs.	540-01210
	V	200 pcs.	540-01220
	W	200 pcs.	540-01230
	X	200 pcs.	540-01240
	Y	200 pcs.	540-01250
	Z	200 pcs.	540-01260

Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

TYPE	Width (W)	Length (L)	Strap Width max. (G)	Ø (D)	Marker tiles per carrier	Pack Cont.	Article-No.
SSC46	11.0	46.0	7.9	3.0	5	10 pcs.	540-01046
SSC56	11.0	56.0	7.9	3.0	7	10 pcs.	540-01056
SSC82	11.0	82.0	7.9	3.0	11	10 pcs.	540-01082
SSC106	11.0	106.0	7.9	3.0	15	10 pcs.	540-01106
SSC134	11.0	134.0	7.9	3.0	20	10 pcs.	540-01134
SSC286	11.0	286.0	7.9	3.0	45	10 pcs.	540-01286
SSCPP (Plastic)	11.0	7.0	7.9	3.0	-	100 pcs.	540-02011

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.