



Fittings with swivel external thread

- HG-SM Straight Swivel External Thread, IP66

Straight swivel brass external thread.

Features and Benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus




HelaGuard HG-SM Straight Swivel External Thread, IP66.

MATERIAL	Polyamide 6.6 (PA66), Nickel Plated Brass (NPB)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

HF ✓

RoHS ✓

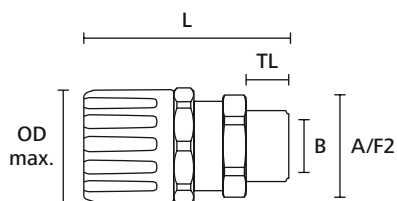

HelaGuard fitting, straight with swivel external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	A/F Thread (A/F2)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG13-SM-M16	13	M16	11.0	24	51	20	12	10 pcs.	Black (BK)	166-21300
HG13-SM-PG9	13	PG9	11.0	24	49	22	10	10 pcs.	Black (BK)	166-21309
HG16-SM-M16	16	M16	11.0	29	57	20	12	10 pcs.	Black (BK)	166-21301
HG16-SM-M20	16	M20	14.5	29	57	24	12	10 pcs.	Black (BK)	166-21302
HG16-SM-PG9	16	PG9	11.0	29	50	22	10	10 pcs.	Black (BK)	166-21310
HG16-SM-PG11	16	PG11	11.0	29	52	24	12	10 pcs.	Black (BK)	166-21311
HG21-SM-M20	21	M20	14.5	32	57	24	12	10 pcs.	Black (BK)	166-21303
HG21-SM-PG13	21	PG13.5	14.5	32	55	24	10	10 pcs.	Black (BK)	166-21312
HG21-SM-PG16	21	PG16	14.5	32	58	29	13	10 pcs.	Black (BK)	166-21313
HG28-SM-M25	28	M25	19.5	44	62	29	12	10 pcs.	Black (BK)	166-21304
HG28-SM-PG21	28	PG21	19.5	44	64	35	14	10 pcs.	Black (BK)	166-21314
HG34-SM-M32	34	M32	26.5	51	67	38	13	10 pcs.	Black (BK)	166-21305
HG34-SM-PG29	34	PG29	26.5	51	68	42	14	10 pcs.	Black (BK)	166-21315
HG42-SM-M40	42	M40	32.5	63	79	50	15	2 pcs.	Black (BK)	166-21306
HG54-SM-M50	54	M50	42.0	76	85	58	17	2 pcs.	Black (BK)	166-21307

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.