



Fittings with swivel internal thread

- HG-45F 45° Elbow Swivel Internal Thread, IP66

45° elbow swivel brass internal thread.

Features and Benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus




HelaGuard HG-45F 45° Elbow Swivel Internal Thread, IP66.

MATERIAL	Polyamide 6.6 (PA66), Nickel Plated Brass (NPB)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

HF ✓

RoHS ✓

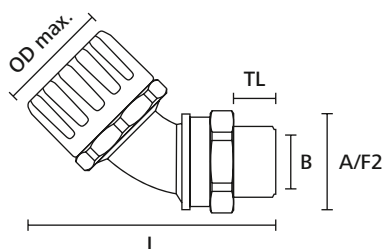

HelaGuard fitting, 45° with swivel internal thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	A/F Thread (A/F2)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG16-45F-M20	16	M20	14.0	29	68	24	14	10 pcs.	Black (BK)	166-23800
HG16-45F-PG16	16	PG16	14.0	29	68	24	14	10 pcs.	Black (BK)	166-23807
HG21-45F-M20	21	M20	14.0	32	75	24	14	10 pcs.	Black (BK)	166-23801
HG21-45F-PG16	21	PG16	14.0	32	75	24	14	10 pcs.	Black (BK)	166-23808
HG28-45F-M25	28	M25	19.0	44	88	29	15	10 pcs.	Black (BK)	166-23802
HG28-45F-PG21	28	PG21	19.0	44	88	29	15	10 pcs.	Black (BK)	166-23809
HG34-45F-M32	34	M32	24.5	51	99	38	16	10 pcs.	Black (BK)	166-23803
HG34-45F-PG29	34	PG29	24.5	51	99	38	16	10 pcs.	Black (BK)	166-23810
HG42-45F-M50	42	M50	39.0	63	115	52	14	2 pcs.	Black (BK)	166-23804
HG54-45F-M50	54	M50	39.0	76	135	52	14	2 pcs.	Black (BK)	166-23805

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.