



Fittings with swivel internal thread

- HGL-45F 45° Elbow Swivel Internal Thread, IP68

45° elbow swivel brass internal thread with conduit seal and washer.

Fulfils IP66, IP67, IP68 and IP69k.


Features and Benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus



HelaGuard HGL-45F 45° Elbow Swivel Internal Thread, IP68.

MATERIAL	Polyamide 6.6 (PA66), Nickel Plated Brass (NPB), Thermoplastic Elastomer (TPE)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

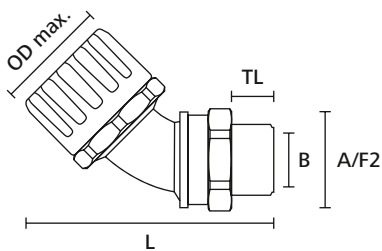

HelaGuard fitting, 45° with swivel internal thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	A/F Thread (A/F2)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HGL16-45F-M20	16	M20	14.0	29	68	24	14	10 pcs.	Black (BK)	166-24400
HGL16-45F-PG16	16	PG16	14.0	29	68	24	14	10 pcs.	Black (BK)	166-24407
HGL21-45F-M20	21	M20	14.0	32	75	24	14	10 pcs.	Black (BK)	166-24401
HGL21-45F-PG16	21	PG16	14.0	32	75	24	14	10 pcs.	Black (BK)	166-24408
HGL28-45F-M25	28	M25	19.0	44	88	29	15	10 pcs.	Black (BK)	166-24402
HGL28-45F-PG21	28	PG21	19.0	44	88	29	15	10 pcs.	Black (BK)	166-24409
HGL34-45F-M32	34	M32	24.5	51	99	38	16	10 pcs.	Black (BK)	166-24403
HGL34-45F-PG29	34	PG29	24.5	51	99	38	16	10 pcs.	Black (BK)	166-24410
HGL42-45F-M50	42	M50	39.0	63	115	52	14	2 pcs.	Black (BK)	166-24404
HGL54-45F-M50	54	M50	39.0	76	135	52	14	2 pcs.	Black (BK)	166-24405

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.