

#### Fittings with swivel flange

- HG-SFL Straight Swivel Flange, IP66

Straight swivel flange.


#### Features and Benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus



HeliaGuard HG-SFL Straight Swivel Flange, IP66.

<b>MATERIAL</b>	Polyamide 6.6 (PA66)
<b>Operating Temperature</b>	-50 °C to +135 °C
<b>Flammability</b>	UL94 V2
<b>Specifications</b>	UL-Recognised

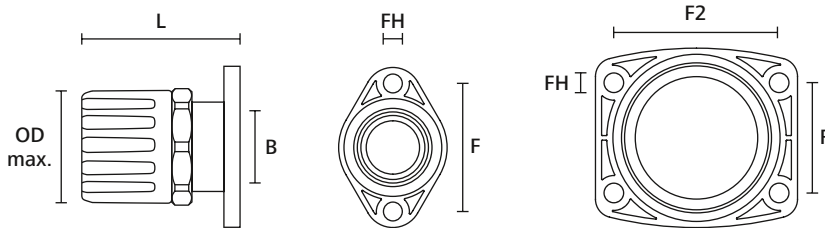

HeliaGuard fitting, straight swivel flange

TYPE	Nominal Ø	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	Hole Ø (FH)	Fixing Hole Centres (F)	Fixing Hole Centres (F2)	Pack Cont.	Colour	Article-No.
HG16-SFL	16	14.5	29	41	5.2	36	-	10 pcs.	Black (BK)	166-21200
HG21-SFL	21	14.5	34	44	5.2	36	-	10 pcs.	Black (BK)	166-21201
HG28-SFL	28	19.5	44	49	6.2	53	-	10 pcs.	Black (BK)	166-21202
HG34-SFL	34	26.5	51	55	6.2	36	54	10 pcs.	Black (BK)	166-21203
HG42-SFL	42	42.0	63	63	6.2	36	54	2 pcs.	Black (BK)	166-21204

All dimensions in mm. Subject to technical changes.  
Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.