



Fittings with swivel flange

- HG-45FL 45° Elbow Swivel Flange, IP66

45° elbow swivel flange.


Features and Benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus



HeliaGuard HG-45FL 45° Elbow Swivel Flange, IP66.

MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

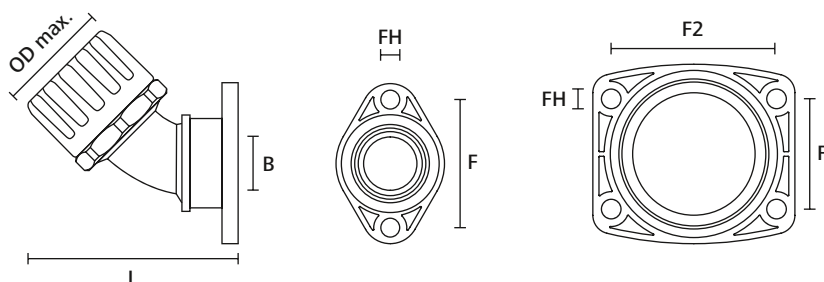

HeliaGuard fitting, 45° swivel flange

TYPE	Nominal Ø	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	Hole Ø (FH)	Fixing Hole Centres (F)	Fixing Hole Centres (F2)	Pack Cont.	Colour	Article-No.
HG16-45FL	16	14.0	29	56	5.2	36	-	10 pcs.	Black (BK)	166-23600
HG21-45FL	21	14.0	34	63	5.2	36	-	10 pcs.	Black (BK)	166-23601
HG28-45FL	28	19.0	44	77	6.2	53	-	10 pcs.	Black (BK)	166-23602
HG34-45FL	34	24.5	51	84	6.2	36	54	10 pcs.	Black (BK)	166-23603
HG42-45FL	42	39.0	63	98	6.2	36	54	2 pcs.	Black (BK)	166-23604

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.