



Fittings with strain relief and cable seal

• HG-SCG Straight Cable Gland Fitting, IP66

Straight fitting with cable seal and strain relief.

Features and Benefits

- Provides strain relief
- Seals cable at IP68 and IP69k
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus




HeliaGuard HG-SCG Straight Cable Gland Fitting, External Thread, IP66.

MATERIAL	Polyamide 6.6 (PA66), Nickel Plated Brass (NPB)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

HF ✓

RoHS ✓

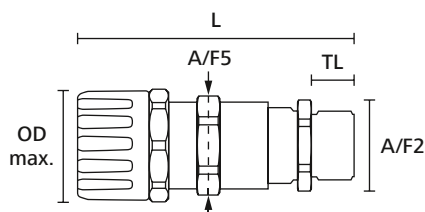

HeliaGuard fitting, straight cable gland

TYPE	Nominal Ø	Thread Size	Suitable for Cable Ø from/to	Outside Ø max (OD max.)	Length (L)	A/F Thread (A/F2)	A/F Gland Body (A/F5)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG13-SCG-M16	13	M16	4.5 - 10	24	72	20	20	12	10 pcs.	Black (BK)	166-21500
HG16-SCG-M16	16	M16	4.5 - 10	29	76	20	20	12	10 pcs.	Black (BK)	166-21501
HG16-SCG-M20	16	M20	7 - 13	29	82	24	24	12	10 pcs.	Black (BK)	166-21502
HG21-SCG-M20	21	M20	7 - 13	32	82	24	24	12	10 pcs.	Black (BK)	166-21503
HG28-SCG-M25	28	M25	9 - 17	44	90	29	29	12	10 pcs.	Black (BK)	166-21504
HG34-SCG-M32	34	M32	11 - 21	51	102	36	38	15	10 pcs.	Black (BK)	166-21505
HG42-SCG-M40	42	M40	19 - 28	63	117	45	50	15	2 pcs.	Black (BK)	166-21506
HG54-SCG-M50	54	M50	27 - 35	76	125	54	56	15	2 pcs.	Black (BK)	166-21507

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.

To ensure the protective seal, it is recommended to use a thread sealant on the thread between the cable gland insert and the conduit fitting.



Please note! Not all products listed on this page may have this approval.