



Connectors, reducers and couplers

• HGL-Y Y-Connector, IP68

Fulfils IP66, IP67, IP68 and IP69k.


Features and Benefits

- Fast fit Y-shaped connector
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus



HelaGuard HGL-Y, Y-Connector with conduit seals.

MATERIAL	Polyamide 6.6 (PA66), Thermoplastic Elastomer (TPE)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

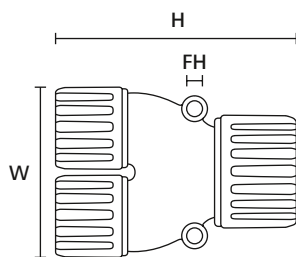

HelaGuard fitting, Y-connector

TYPE	From nominal diameter	To nominal diameter	Width (W)	Height (H)	Hole Ø (FH)	Pack Cont.	Colour	Article-No.
HGL16-Y13	16	13	49	77	4.0	5 pcs.	Black (BK)	166-25901
HGL21-Y16	21	16	59	89	5.0	3 pcs.	Black (BK)	166-25902
HGL28-Y21	28	21	67	93	6.0	3 pcs.	Black (BK)	166-25903
HGL34-Y28	34	28	90	116	6.5	2 pcs.	Black (BK)	166-25904

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.