

Connectors, reducers and couplers

- **HG-R Reducer, IP66**


Features and Benefits

- Reduce size of connector to attach smaller size conduits
- Used with T-Connector and Y-Connectors
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus



HG-R Reducer.

MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-50 °C to +135 °C
Specifications	UL-Recognised

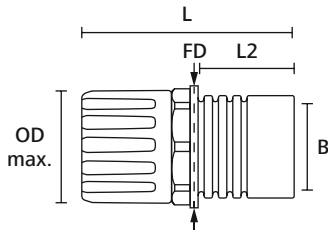

HeliaGuard fitting, reducer

TYPE	From nominal diameter	To nominal diameter	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	Length (L2)	Face Diameter (FD)	Pack Cont.	Colour	Article-No.
HG13-R16	16	13	11.7	24	43	17	23	10 pcs.	Black (BK)	166-25000
HG13-R21	21	13	11.7	24	49	23	30	10 pcs.	Black (BK)	166-25001
HG16-R21	21	16	14.5	29	51	23	30	5 pcs.	Black (BK)	166-25002
HG16-R34	34	16	14.5	29	58	30	44	5 pcs.	Black (BK)	166-25005
HG21-R28	28	21	17.5	32	58	29	34	5 pcs.	Black (BK)	166-25004
HG21-R34	34	21	17.5	32	60	30	44	5 pcs.	Black (BK)	166-25007
HG21-R42	42	21	17.5	32	60	30	50	3 pcs.	Black (BK)	166-25010
HG25-R28	28	25	22.5	39	62	29	34	5 pcs.	Black (BK)	166-25003
HG28-R34	34	28	25.7	44	65	30	44	5 pcs.	Black (BK)	166-25006
HG28-R42	42	28	25.7	44	65	30	50	3 pcs.	Black (BK)	166-25009
HG34-R42	42	34	31.5	51	67	30	50	3 pcs.	Black (BK)	166-25008

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.