



Fittings for metallic conduits

• SSC-SM Swivel External Thread

Swivel external thread, stainless steel (SS316).

Features and Benefits

- Two-part fitting of shell and body with external thread
- Highly resistant to rust and corrosion
- External thread swivels about main body
- Provides tight, reliable hold of conduit
- Can be secured with locknut




HeliaGuard SSC-SM Swivel External Thread.

MATERIAL	Stainless Steel (SS316)
Operating Temperature	-100 °C to +400 °C

HF ✓

RoHS ✓

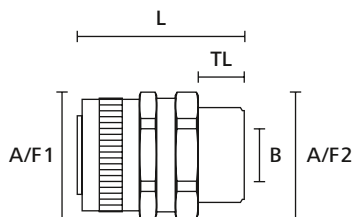

HeliaGuard fitting, straight with swivel external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	A/F Thread (A/F2)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
SSC10-SM-M12	10	M12	5.6	30.2	14	14	8.0	1 pcs.	Metal (ML)	166-30419
SSC12-SM-M16	12	M16	8.5	32.2	19	19	8.0	1 pcs.	Metal (ML)	166-30420
SSC16-SM-M16	16	M16	11.5	34.2	19	19	10.0	1 pcs.	Metal (ML)	166-30421
SSC20-SM-M20	20	M20	15.3	35.5	24	24	10.0	1 pcs.	Metal (ML)	166-30422
SSC25-SM-M25	25	M25	19.1	43.7	29	29	10.0	1 pcs.	Metal (ML)	166-30423
SSC32-SM-M32	32	M32	26.2	48.0	38	38	13.0	1 pcs.	Metal (ML)	166-30424

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.