



Fittings for metallic conduits with liquid-tight cover

- LTS-45FMC 45° Elbow Compression Fitting, IP68**

External thread, nickel plated brass.

Fulfils IP66, IP67, IP68 and IP69k.


Features and Benefits

- Multipart 45° compression fitting including polyamide seal
- Provides excellent tensile strength



HeliaGuard LTS-45FMC 45° Elbow Compression Fitting.

MATERIAL	Nickel Plated Brass (NPB), Polyamide 6 (PA6)
Operating Temperature	-40 °C to +135 °C

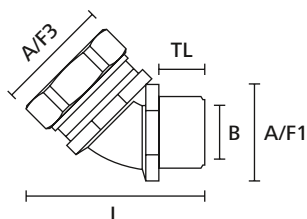

HeliaGuard compression fitting, 45° with fixed external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	A/F Nut (A/F3)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
LTS16-45FMC-M20	16	M20	10.7	44.8	24	26	13.0	10 pcs.	Metal (ML)	166-32500
LTS20-45FMC-M20	20	M20	14.5	49.5	24	29	13.0	10 pcs.	Metal (ML)	166-32501
LTS25-45FMC-M25	25	M25	18.0	63.0	30	35	14.0	10 pcs.	Metal (ML)	166-32502
LTS32-45FMC-M32	32	M32	24.6	76.6	36	42	15.0	2 pcs.	Metal (ML)	166-32503
LTS40-45FMC-M40	40	M40	32.7	86.9	47	57	18.0	1 pcs.	Metal (ML)	166-32504
LTS50-45FMC-M50	50	M50	37.7	93.4	61	62	18.0	1 pcs.	Metal (ML)	166-32505
LTS63-45FMC-M63	63	M63	49.0	111.0	67	76	20.0	1 pcs.	Metal (ML)	166-32506

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.