



Fittings for metallic conduits with liquid-tight cover

• LTS-LTS Compression Coupler, IP68

Nickel plated brass.

Fulfils IP66, IP67, IP68 and IP69k.


Features and Benefits

- Multipart compression coupler including polyamide seal
- Joins two conduits
- Provides excellent tensile strength



HeliaGuard LTS-LTS Compression Coupler.

MATERIAL	Nickel Plated Brass (NPB), Polyamide 6 (PA6)
Operating Temperature	-40 °C to +135 °C

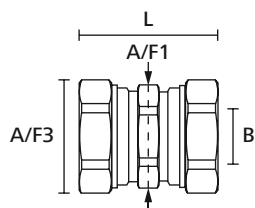

HeliaGuard compression coupler

TYPE	Nominal Ø	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	A/F Nut (A/F3)	Pack Cont.	Colour	Article-No.
LTS20-LTS20	20	14.5	39.5	26	29	10 pcs.	Metal (ML)	166-32600
LTS25-LTS25	25	18.0	46.9	33	35	10 pcs.	Metal (ML)	166-32601

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.