



Spiral-reinforced PVC Conduits

• PSRSC Conduit

Machine building, plant construction, shipbuilding, automation, electrical installations


Features and Benefits

- Flexible
- Easy to clean outside surface
- Withstands some torsional movement
- Self-extinguishing
- Easy to feed cables
- Can be used with PSR PA66 fittings and PSRSC metal fittings
- Colour: grey; black, orange (highly flexible), green (oil resistant), blue (high temperature resistant) upon request



PSRSC allows for easy insertion of cables and cleaning of outside surface.

MATERIAL	Polyvinylchloride (PVC)
Operating Temperature	-5 °C to +70 °C
Flammability	self-extinguishing according to EN IEC 61386
Specifications	EU 10/2011

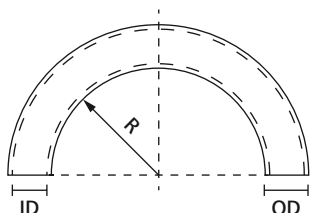

HelaGuard spiral-reinforced conduit, smooth outer coating

PSRSC conduit with higher flexibility (colour: orange), higher resistance to oil (colour: green) or to temperature (colour: blue) available on request.

TYPE	Nominal Ø	Outside Ø (OD)	Inside Ø (ID)	Min. Bending Radius (R)	Weight (g/m)	Reel Length	Colour	Article-No.
PSRSC12	12	14.2	10.0	50	76	30 m	Grey (GY)	166-40301
PSRSC16	16	17.8	12.0	50	139	30 m	Grey (GY)	166-40302
PSRSC20	20	21.1	16.0	70	174	30 m	Grey (GY)	166-40303
PSRSC25	25	26.4	21.0	90	235	30 m	Grey (GY)	166-40304
PSRSC32	32	33.1	26.5	140	327	30 m	Grey (GY)	166-40305
PSRSC40	40	41.8	35.4	190	448	30 m	Grey (GY)	166-40306
PSRSC50	50	47.9	40.0	240	725	30 m	Grey (GY)	166-40307
PSRSC63	63	59.7	51.3	270	948	30 m	Grey (GY)	166-40308

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.