

Fittings for spiral-reinforced PVC Conduits

• PSRSC-SMC swivel compression fitting

Straight fitting, swivel external thread, nickel plated brass.

Fulfils IP66, IP67, IP68 and IP69k with PSRSC conduits.


Features and Benefits

- Multipart compression fitting including elastomeric seal
- Can be used for knockouts or threaded entries as fitting rotates until tightened
- Fits PSRSC conduits



HeliaGuard PSRSC-SMC Swivel Compression Fitting.

MATERIAL	Nickel Plated Brass (NPB), Polyamide 6 (PA6)
Operating Temperature	-40 °C to +135 °C

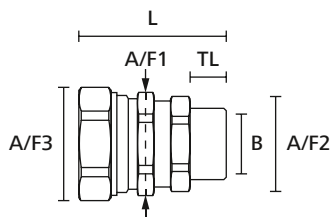

HeliaGuard compression fitting, straight with swivel external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	A/F Thread (A/F2)	A/F Nut (A/F3)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
PSRSC16-SMC-M16	16	M16	10.7	40.9	24	24	26	10.0	10 pcs.	Metal (ML)	166-41101
PSRSC16-SMC-M20	16	M20	10.7	41.0	24	24	26	10.0	10 pcs.	Metal (ML)	166-41102
PSRSC20-SMC-M20	20	M20	14.5	41.8	26	26	29	10.0	10 pcs.	Metal (ML)	166-41103
PSRSC25-SMC-M25	25	M25	18.0	50.7	33	29	35	12.0	10 pcs.	Metal (ML)	166-41104
PSRSC32-SMC-M32	32	M32	24.6	56.9	40	38	42	13.0	2 pcs.	Metal (ML)	166-41105

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.