

Fittings for spiral-reinforced PVC Conduits

• PSRSC-FMCSS compression fitting

Straight fitting, external thread, stainless steel (SS316).

Fulfils IP66, IP67, IP68 and IP69k with PSRSC conduits.


Features and Benefits

- Multipart stainless steel (SS316) compression fitting including elastomeric seal
- Can be used for knockouts or threaded entries as fitting rotates until tightened
- Fits PSRSC conduits



PSRSC-FMCSS Straight Compression Fitting.

MATERIAL	Stainless Steel (SS316), Polyamide 6 (PA6)
Operating Temperature	-40 °C to +135 °C

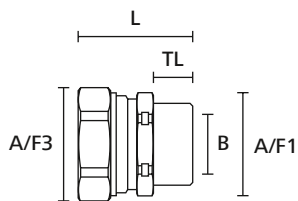

HelaGuard compression fitting, straight with fixed external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	A/F Nut (A/F3)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
PSRSC16-FMCSS-M16	16	M16	10.7	33.0	24	26	12.0	1 pcs.	Metal (ML)	166-41301
PSRSC16-FMCSS-M20	16	M20	10.7	33.0	24	26	12.0	1 pcs.	Metal (ML)	166-41302
PSRSC20-FMCSS-M20	20	M20	14.5	33.5	26	29	12.0	1 pcs.	Metal (ML)	166-41303
PSRSC25-FMCSS-M25	25	M25	18.0	40.5	33	35	14.0	1 pcs.	Metal (ML)	166-41304
PSRSC32-FMCSS-M32	32	M32	24.6	45.8	40	42	15.0	1 pcs.	Metal (ML)	166-41305

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.