

Fittings for spiral-reinforced PVC Conduits

- **PSRSC-90FMCSS 90° compression fitting**

90° fitting, fixed external thread, stainless steel (SS316).

Fulfils IP66, IP67, IP68 and IP69k with PSRSC conduits.


Features and Benefits

- Multipart 90° stainless steel (SS316) compression fitting including elastomeric seal
- Can be used for knockouts or threaded entries as fitting rotates until tightened
- Fits PSRSC conduits



HeliaGuard PSRSC-90FMCSS 90° Elbow Compression Fitting.

MATERIAL	Stainless Steel (SS316), Polyamide 6 (PA6)
Operating Temperature	-40 °C to +135 °C

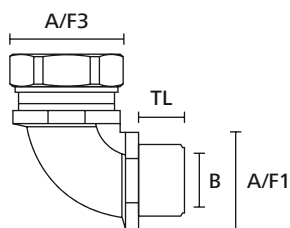

HeliaGuard compression fitting, 90° with fixed external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	A/F Body (A/F1)	A/F Nut (A/F3)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
PSRSC16-90FMCSS-M20	16	M20	10.7	24	26	13.0	1 pcs.	Metal (ML)	166-41401
PSRSC20-90FMCSS-M20	20	M20	14.5	24	29	13.0	1 pcs.	Metal (ML)	166-41402
PSRSC25-90FMCSS-M25	25	M25	18.0	30	35	14.0	1 pcs.	Metal (ML)	166-41403
PSRSC32-90FMCSS-M32	32	M32	24.6	36	42	15.0	1 pcs.	Metal (ML)	166-41404

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.