




HelaGuard accessories

ALNPB Nickel plated brass locknuts

The ALNPB hexagonal locknut is used to secure fitting.



HelaGuard ALNPB Nickel Plated Brass Locknuts.

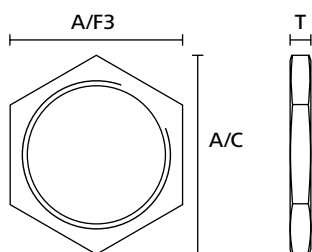

HelaGuard locknut

MATERIAL	Nickel Plated Brass (NPB)
Operating Temperature	-100 °C to +300 °C



TYPE	Thread Size	A/F Nut (A/F3)	Across Corners (A/C)	Thickness (T)	Pack Cont.	Colour	Article-No.
ALNPB-M12	M12	15	17	3.5	10 pcs.	Metal (ML)	166-50100
ALNPB-M16	M16	20	23	3.5	10 pcs.	Metal (ML)	166-50101
ALNPB-M20	M20	24	28	3.5	10 pcs.	Metal (ML)	166-50102
ALNPB-M25	M25	29	33	3.5	10 pcs.	Metal (ML)	166-50103
ALNPB-M32	M32	38	43	4.5	2 pcs.	Metal (ML)	166-50104
ALNPB-M40	M40	48	54	5.0	1 pc.	Metal (ML)	166-50105
ALNPB-M50	M50	58	66	6.0	1 pc.	Metal (ML)	166-50106
ALNPB-M63	M63	70	79	6.5	1 pc.	Metal (ML)	166-50107
ALNPB-M75	M75	84	94	7.0	1 pc.	Metal (ML)	166-50108
ALNPB-PG7	PG7	15	17	2.8	10 pcs.	Metal (ML)	166-50109
ALNPB-PG9	PG9	20	23	3.5	10 pcs.	Metal (ML)	166-50110
ALNPB-PG11	PG11	22	25	3.5	10 pcs.	Metal (ML)	166-50111
ALNPB-PG13	PG13,5	24	28	3.5	10 pcs.	Metal (ML)	166-50112
ALNPB-PG16	PG16	26	30	3.6	10 pcs.	Metal (ML)	166-50113
ALNPB-PG21	PG21	33	37	3.7	10 pcs.	Metal (ML)	166-50114
ALNPB-PG29	PG29	42	46	4.0	1 pc.	Metal (ML)	166-50115
ALNPB-PG36	PG36	52	57	5.0	1 pc.	Metal (ML)	166-50116
ALNPB-PG42	PG42	60	65	5.0	1 pc.	Metal (ML)	166-50117
ALNPB-PG48	PG48	64	70	5.0	1 pc.	Metal (ML)	166-50118

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.

