


## Technical data sheet

Article number:  
156-01754

**T18RFT6**

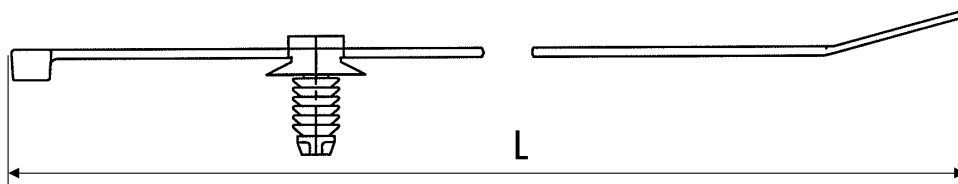

|                                      |                                                                                                           |
|--------------------------------------|-----------------------------------------------------------------------------------------------------------|
| <b>Product Group</b>                 | 2-Piece Fixing Ties with Fir Tree, with Disc, for Round Holes                                             |
| <b>Product Family</b>                | Fir tree parts FT6                                                                                        |
| <b>Material</b>                      | Polyamide 6.6, heat stabilised (PA66HS), Polyamide 6.6, high impact modified, heat stabilised (PA66HIRHS) |
| <b>Colour</b>                        | Black (BK)                                                                                                |
| <b>Application Tool</b>              | MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP                                       |
| <b>Bundle Ø max.</b>                 | 18.0 mm                                                                                                   |
| <b>Bundle Ø min.</b>                 | 4.0 mm                                                                                                    |
| <b>Cable Tie</b>                     | Polyamide 6.6, heat stabilised (PA66HS)                                                                   |
| <b>Fixation Method</b>               | Fir Tree                                                                                                  |
| <b>Flammability</b>                  | UL 94 HB                                                                                                  |
| <b>Foot Part</b>                     | Polyamide 6.6, high impact modified, heat stabilised (PA66HIRHS)                                          |
| <b>for Hole Ø (FH)</b>               | 6.4 - 7.1 mm                                                                                              |
| <b>Height (H)</b>                    | 1.0 mm                                                                                                    |
| <b>Length (L)</b>                    | 100 mm                                                                                                    |
| <b>Length (L2)</b>                   | 11.6 mm                                                                                                   |
| <b>Min.Tensile Strength</b>          | 80 N                                                                                                      |
| <b>Operating Temperature</b>         | -40 °C to +105 °C                                                                                         |
| <b>Package Content packed in</b>     | bag                                                                                                       |
| <b>Pack Cont.</b>                    | 1000 pcs.                                                                                                 |
| <b>Panel Thickness</b>               | 3.00 mm                                                                                                   |
| <b>Panel Thickness min. (metric)</b> | 0.75 mm                                                                                                   |
| <b>ROHS compliant</b>                | Yes                                                                                                       |
| <b>Variant</b>                       | Inside Serrated                                                                                           |
| <b>Width (W)</b>                     | 2.5 mm                                                                                                    |

