



Common Mode Choke

TCK-075


Order Code	TCK-075
Inductance (each winding)	33.3 μ H \pm 20% (at 10 kHz / 50 mV)
Impedance (DCR)	8.5 m Ω max.
Rated Current	4 A max.
Rated Voltage	500 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-075

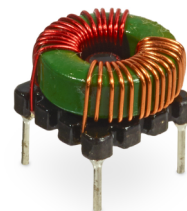

Impedance Curve

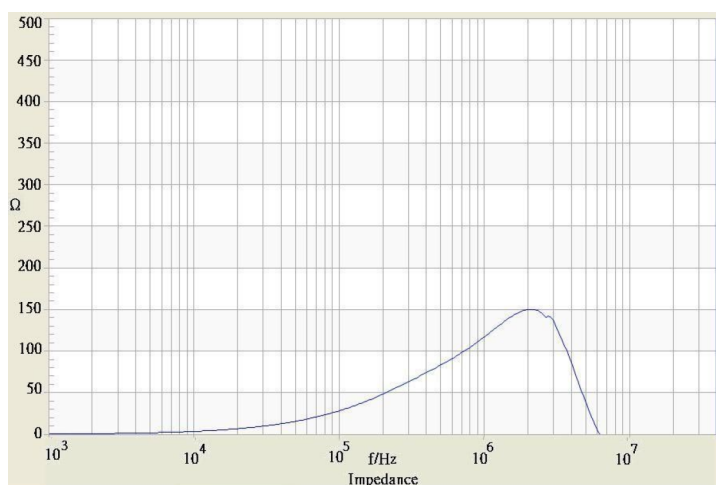

Outline Dimensions

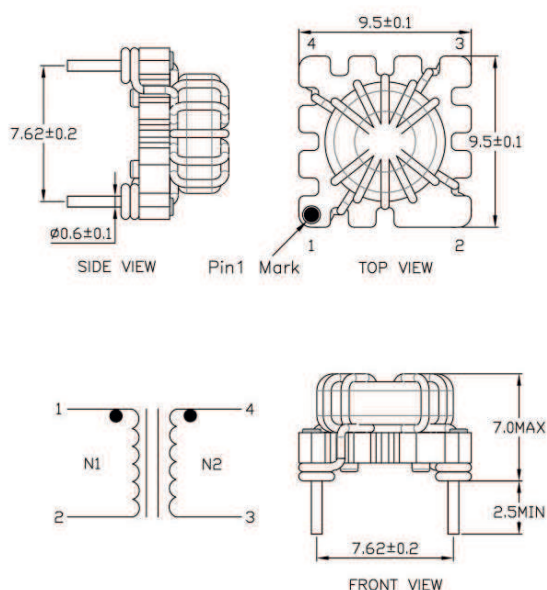

All specifications valid at +25°C, unless otherwise stated.