


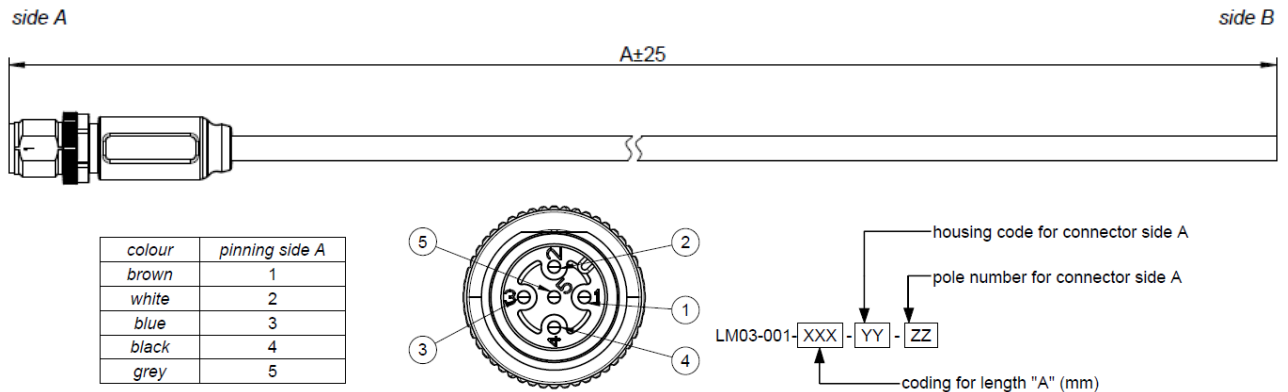

All dimensions are in mm

Product properties

Standard	DIN EN 61076-2-101
Product type	Sensor actuator cable
Connector	MI5S101-1M03-YY-05 (see connector data sheet)
Shielding	360°
Number of contacts	5 x male
Thread type	M12
Coding	A-standard
Standard length (A)	0,3m - 0,5m - 1,0m - 1,5m - 2,0m - 2,5m - 3,0m - 5,0m - 10,0m

Cable data

Type	LIF9Y-FCF11Y
Specification	UL 758/1581 FT2
Core	5 x 0,34 mm ²
Core colours	brown, white, blue, black, grey
Jacket	PUR, black
Other	suitable for drag chain

Packaging

Standard	bag
----------	-----

Coding

coding	LM03-001-XXX-YY-ZZ
	-A0
-YY	

While the information has been carefully compiled to the best of our knowledge, nothing is intended as representation or warranty on our part and no statement herein shall be construed as recommendation to infringe existing patents. In the effort to improve our products, we reserve the right to make changes judged to be necessary.

For the installation of the electrotechnical equipment, particular electrotechnical expertise is required.



Draft	Date	Approved	Date	Rev.	Engineering change number	Name	Date
F. Wein	16.07.24	F.Wein	17.03.25	600	25-v116	S. Mochti	17.03.25