

Diffused ball addressable RGB led string light



◆ Product Description:

RGB LED with Micro Ic built in;

DC5V, 20 LEDs per string, 3m per string;

Pixel pitch 150mm;


3Pin JST SM male and female connector on each end.



◆ Product parameter

Product Number	P015001TA3SF6
Voltage	DC5V
Power/string	0.1W
LED Qty/string	20
Color	RGB
Pixel/string	20
Lamp distance	150mm
Control	SPI

◆ Outline Dimension (unit: mm)

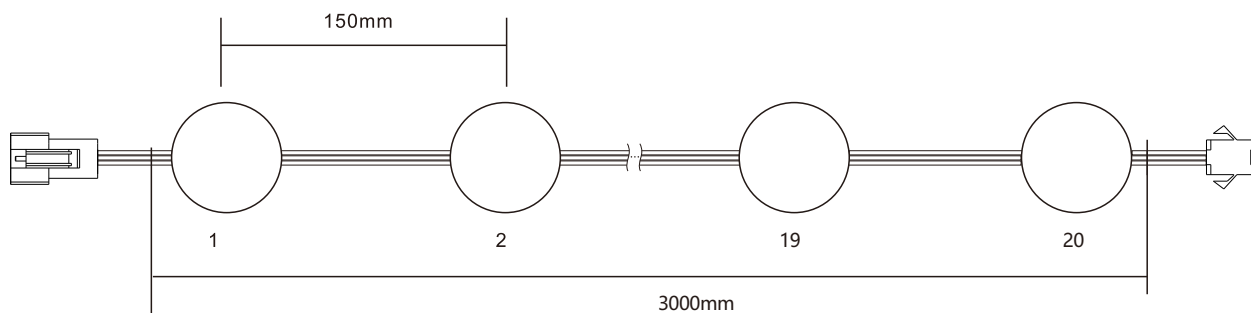

Note: The parameters are subject to change without notice!