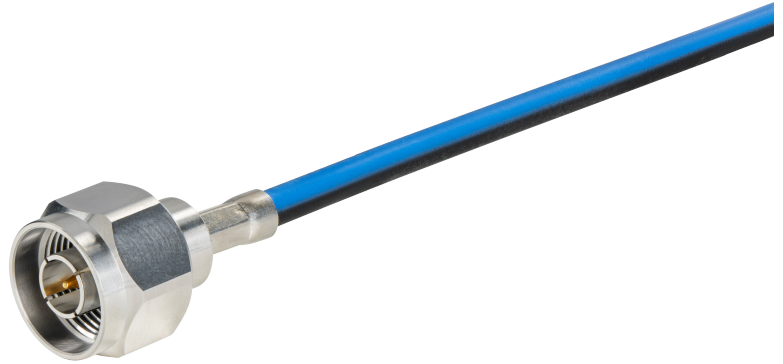


COAXIAL CONNECTOR, N, 50 Ohm, Straight cable plug (male)

11_N-50-3-74/133_N

Properties

- Lead free material
- RoHS full compliant without exemption 6C
- Interface dimensions according IEC/MIL

**Product configuration**

Interface type	Gender	Standard
N	plug	IEC 61169-16_MIL-STD-348A/304_CECC 22210

Interface and material data

Piece parts	Material	Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer conductor	Brass	SUCOPLATE (R) Plating
Body	Brass	SUCOPLATE (R) Plating
Insulator	PTFE (Polytetrafluoroethylene)	
Coupling nut	Brass	SUCOPLATE (R) Plating
Gasket	VMQ (Silicone rubber)	
Crimp ferrule	Copper	SUCOPLATE (R) Plating

Electrical data

Impedance	50 Ω
Interface frequency	11 GHz

Mechanical data

Weight	24.072 g
Mating cycles	500
Cable entry centre contact	crimped
Cable entry outer contact	crimped

Environmental data

Operation temperature	-65 °C ... 165 °C
-----------------------	-------------------

COAXIAL CONNECTOR, N, 50 Ohm, Straight cable plug (male)
11_N-50-3-74/133_N

Ordering Information Table		
Item number	Item description	Packaging type
85240399	11_N-50-3-74/133_NH	Bulk 100 pcs

Suitable cables	
Cable group	U9 - 3 mm / 50 Ohm
Suitable cables	RG_142_B/U
	ENVIROFLEX_142
	RG_223_/U
	K_03252_D-03
	RADOX_RF_142

Additional Information	
Only as assembly	No

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/ EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P51608 / Date of publication: 23.10.2024 / uncontrolled copy